


Kompakt samleskinnestøtte for kraftdistribusjon, ECBS

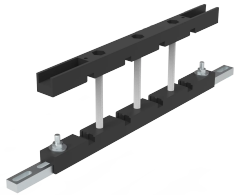

This busbar support, ECBS, is available for one or two bars up to 80 x 5 mm or one bar up to 80 x 10 mm. The support can be mounted both horizontally and vertically. It is available off the shelf and tested according to IEC 61439.

FUNKSJONER

Beskrivelse: Busbar support up to 1600A to be mounted horizontally or vertically. Mounts directly to the enclosure frame or with help of CLPF profiles. Available in single and double bar per phase for bar thickness 5 mm and only single bar per phase for bar thickness 10 mm, and width from 25 to 80 mm.

Arbeidstemperatur: -40°C up to 130°C.

Materiale: Reinforced polyamide and steel. Halogen free.

Levering: Busbar support with mounting material.

SPESIFIKASJONER

Table 1/1						
Katalognummer	E-nummer	Innkapslingsmateriale	Produktfamilie	Materiale	Avslutt	Farge
ECBS110TN	2420660	Mild stål	Frittstående	Polyamid, Stål	Glatt matte	Svart
ECBS205TN	2420659	Mild stål	Frittstående	Plast, Mild stål	Jevn	

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE