


CS480 rett rør

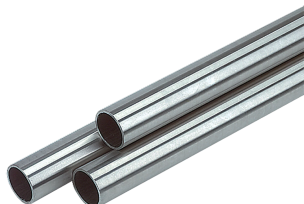

CS480 Straight Tube provides structural integrity and acts as conduit for equipment wiring.

BRANSJESTANDARDER

IEC 60529, IP66

FUNKSJONER

Wall thickness 3.6-mm

Outer diameter of 48.3-mm

Assembled CS480 HMI Arm System has a max weight load of 89.6 lb. (40.7 kg)

SPESIFIKASJONER

Avslutt: Politisert
Materiale: Rustfritt stål 304

Table 1/1

Katalognummer	Høyde	Bredde	Dybde	Tykkelse	Hurtiglevering
CCSS48T150	1500mm	48mm	48mm	3.6mm	Nei
CCSS48T75	750mm	48mm	48mm	3.6mm	Nei
CCSS48T125	1250mm	48mm	48mm	3.6mm	Nei
CCSS48T100	1000mm	48mm	48mm	3.6mm	Nei
CCSS48T25	250mm	48mm	48mm	3.6mm	Nei
CCSS48T50	500mm	48mm	48mm	3.6mm	Nei

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE