


Varmevifte med termostat, ECR

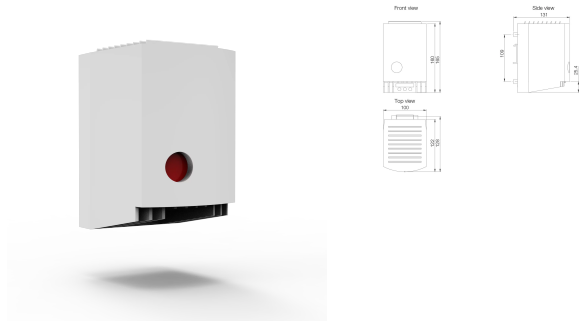

Varmeapparatet med høy ytelse, ECR, har en integrert termostat og en varmekapasitet på 550 watt. Det brukes en vifte til å fordele varmen som genereres jevnt gjennom hele skapet, dette betyr at varme områder kan forhindres. Den eliminerer vannkondens, også når omgivelsestemperaturen faller kraftig. Den forhåndsinstallerte integrerte termostaten vil spare plass inne i skapet og redusere installasjonstiden sammenlignet med en separat montert termostat.

BRANSJESTANDARDER

cRUus_UL

CE

EAC

FUNKSJONER

Beskrivelse: Høy presterende varme vifte

Materiale: Plast i hht. UL94 V-0.

innstillingsområde: 0 °C to 60 °C.

Varmeelement: PTC-resistor, temperatur begrensende.

Levetid på vifte: 50.000 h at 25 °C.

Driftstemperatur: -45 °C til +70 °C.

Tilkobling: 2 pole klemme 2.5 mm², moment 0.8 Nm max.

Tetthetsgrad: IP 20 / Klasse II (dobbelisolert).

Godkjenninger: CE

Overflatebehandling: Lyse grå.

Pakning: 1 stk.

High performance fan heater with a 550 watt heating capacity, and integrated thermostat

The large amount of heat generated by the optimised sized heater is distributed within the enclosure using forced air, produced by the heater's fan

Customers save installation time as the thermostat is integrated into the fan heater and therefore does not need to be connected

When installed, water condensation will be avoided especially in situations when the ambient temperature dramatically drops

As the air will be distributed by the integrated fan, hot spots within the enclosure will be prevented

Customer's labour costs are reduced due to not having to install a separate thermostat, which also saves vital space inside the enclosure

Voltage (V): 220-240 V AC, 50/60 Hz

SPESIFIKASJONER

Table 1/1						
Katalognummer	E-nummer	Høyde	Bredde	Dybde	Materiale	Avslutt
ECR550	4913264	160mm	100mm	122mm	Plast	Jevn

YTTERLIGERE PRODUKTDETALJER

Spennings (V): 100-120 V AC på forespørsel.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE