

ELFB taper form bolt



The ELFB taper bolt is used to firmly attach a nVent LENTON taper-threaded coupler onto formwork in precast and cast-in-place construction. This reusable form saving accessory allows forms to be pre-drilled with the correct spacing of the reinforcing steel, which speeds construction and allows the forms to be re-used on repetitive construction elements. This system can be used in conjunction with coupler boxes to eliminate the use of bend-out-boxes and also helps eliminate protruding dowel bars.

The screw-in bolt is designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour. The bolt eliminates the need for form saving plates and simplifies the use of standard couplers in form saving applications.

FUNKSJONER

Multiple lengths available depending on form thickness

Used in both form saving and coupler box applications

Bar end protector included to protect the nVent LENTON taper thread

Durable, re-usable and long lasting

Saves time and money

SPESIFIKASJONER

Materiale: Stål

Table 1/2

Katalognummer	Mutter inkludert	Formtykkelse (FT)	Armeringstørrelse, metrisk	Armeringstr., US	Armeringsjern, Canada	Lengde (L)
ELFB10X003	Nei	3 mm	10 mm	#3		21mm
ELFB12X003	Nei	3 mm	12 mm	#4	10M.	21mm
ELFB10X020	Ja	3 - 20 mm	10 mm	#3		55mm

Katalognummer	Mutterinkludert	Formtykkelse (FT)	Armeringstørrelse, metrisk	Armeringstr., US	Armeringsjern, Canada	Lengde (L)
ELFB12X010	Nei	3 - 10 mm	12 mm	#4	10M.	28mm
ELFB14X003	Nei	3 mm	14 mm			25mm
ELFB10X040	Ja	3 - 40 mm	10 mm	#3		75mm
ELFB12X020	Ja	3 - 20 mm	12 mm	#4	10M.	60mm
ELFB16X003	Nei	3 mm	16 mm	#5	15M.	28mm
ELFB18X003	Nei	3 mm	18 mm			33mm
ELFB20X003	Nei	3 mm	20 mm	#6	20M.	38mm
ELFB22X003	Nei	3 mm	22 mm	#7		40mm
ELFB25X003	Nei	3 mm	25 mm	#8	25M.	43mm
ELFB28X003	Nei	3 mm	28 mm	#9	30M.	45mm
ELFB30X003	Nei	3 mm	30 mm			55mm
ELFB32X003	Nei	3 mm	32 mm	#10		49mm
ELFB34X003	Nei	3 mm	34 mm			59mm
ELFB36X003	Nei	3 mm	36 mm	#11	35M.	56mm
ELFB16X010	Nei	3 - 10 mm	16 mm	#5	15M.	35mm
ELFB20X010	Nei	3 - 10 mm	20 mm	#6	20M.	45mm
ELFB14X020	Ja	3 - 20 mm	14 mm			65mm
ELFB16X020	Ja	3 - 20 mm	16 mm	#5	15M.	70mm

Katalognummer	Mutterinkludert	Formtykkelse (FT)	Armeringstørrelse, metrisk	Armeringstr., US	Armeringsjern, Canada	Lengde (L)
ELFB18X020	Ja	3 - 20 mm	18 mm			75mm
ELFB20X020	Ja	3 - 20 mm	20 mm	#6	20M.	90mm
ELFB22X020	Ja	3 - 20 mm	22 mm	#7		90mm
ELFB25X020	Ja	3 - 20 mm	25 mm	#8	25M.	100mm
ELFB28X020	Ja	3 - 20 mm	28 mm	#9	30M.	100mm
ELFB30X020	Ja	3 - 20 mm	30 mm			110mm
ELFB32X020	Ja	3 - 20 mm	32 mm	#10		110mm
ELFB34X020	Ja	3 - 20 mm	34 mm			120mm
ELFB36X020	Ja	3 - 20 mm	36 mm	#11	35M.	115mm
ELFB12X040	Ja	3 - 40 mm	12 mm	#4	10M.	80mm
ELFB14X040	Ja	3 - 40 mm	14 mm			85mm
ELFB16X040	Ja	3 - 40 mm	16 mm	#5	15M.	90mm
ELFB18X040	Ja	3 - 40 mm	18 mm			95mm
ELFB20X040	Ja	3 - 40 mm	20 mm	#6	20M.	105mm
ELFB22X040	Ja	3 - 40 mm	22 mm	#7		110mm
ELFB25X040	Ja	3 - 40 mm	25 mm	#8	25M.	115mm
ELFB28X040	Ja	3 - 40 mm	28 mm	#9	30M.	120mm
ELFB30X040	Ja	3 - 40 mm	30 mm			130mm

Katalognummer	Mutterinkludert	Formtykkelse (FT)	Armeringstørrelse, metrisk	Armeringstr., US	Armeringsjern, Canada	Lengde (L)
ELFB32X040	Ja	3 - 40 mm	32 mm	#10		130mm
ELFB34X040	Ja	3 - 40 mm	34 mm			140mm
ELFB36X040	Ja	3 - 40 mm	36 mm	#11	35M.	135mm

Table 2/2				
Katalognummer	Ytre diameter (OD)	Sokkel bredde (SW)	Vekt på enhet	Antall skiver
ELFB10X003	12 mm	18mm	0.04 kg	2
ELFB12X003	14 mm	21mm	0.06 kg	2
ELFB10X020	12 mm	18mm	0.08 kg	1
ELFB12X010	14 mm	21mm	0.08 kg	4
ELFB14X003	16 mm	24mm	0.09 kg	2
ELFB10X040	12 mm	18mm	0.1 kg	1
ELFB12X020	14 mm	21mm	0.12 kg	1
ELFB16X003	20 mm	30mm	0.14 kg	2
ELFB18X003	20 mm	30mm	0.17 kg	2
ELFB20X003	24 mm	36mm	0.27 kg	2
ELFB22X003	24 mm	36mm	0.29 kg	2
ELFB25X003	30 mm	46mm	0.52 kg	2
ELFB28X003	30 mm	46mm	0.55 kg	2
ELFB30X003	30 mm	46mm	0.71 kg	4

Katalognummer	Ytre diameter (OD)	Sokkel bredde (SW)	Vekt på enhet	Antall skiver
ELFB32X003	36 mm	55mm	0.92 kg	2
ELFB34X003	36 mm	55mm	1.16 kg	4
ELFB36X003	36 mm	55mm	1 kg	2
ELFB16X010	20 mm	30mm	0.2 kg	4
ELFB20X010	24 mm	36mm	0.36 kg	4
ELFB14X020	16 mm	24mm	0.17 kg	1
ELFB16X020	20 mm	30mm	0.3 kg	1
ELFB18X020	20 mm	30mm	0.32 kg	1
ELFB20X020	24 mm	36mm	0.54 kg	1
ELFB22X020	24 mm	36mm	0.55 kg	1
ELFB25X020	30 mm	46mm	1 kg	1
ELFB28X020	30 mm	46mm	1.06 kg	1
ELFB30X020	30 mm	46mm	1.11 kg	1
ELFB32X020	36 mm	55mm	1.73 kg	1
ELFB34X020	36 mm	55mm	1.81 kg	1
ELFB36X020	36 mm	55mm	1.81 kg	1
ELFB12X040	14 mm	21mm	0.14 kg	1
ELFB14X040	16 mm	24mm	0.2 kg	1


Katalognummer	Ytre diameter (OD)	Sokkel bredde (SW)	Vekt på enhet	Antall skiver
ELFB16X040	20 mm	30mm	0.34 kg	1
ELFB18X040	20 mm	30mm	0.36 kg	1
ELFB20X040	24 mm	36mm	0.58 kg	1
ELFB22X040	24 mm	36mm	0.62 kg	1
ELFB25X040	30 mm	46mm	1.09 kg	1
ELFB28X040	30 mm	46mm	1.16 kg	1
ELFB30X040	30 mm	46mm	1.21 kg	1
ELFB32X040	36 mm	55mm	1.87 kg	1
ELFB34X040	36 mm	55mm	1.95 kg	1
ELFB36X040	36 mm	55mm	1.95 kg	1

YTTERLIGERE PRODUKTDETALJER

Length dimension is for reference only.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMER

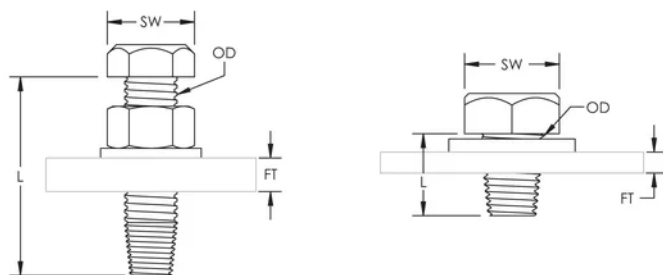

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

Nord-Amerika

+1.800.753.9221

Alternativ 1 –

Kundeservice

Alternativ 2 – Teknisk
støtte

Europa

Nederland:

+31 800-0200135

Frankrike:

+33 800 901 793

Europa

Tyskland:

800 1890272

Andre land:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE