

T-serien Vertical Transition Sleeve



FUNKSJONER

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice different diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

SPESIFIKASJONER

Avslutt:	Vanlig
Hylse:	Standardlengde
Materiale:	Stål
100% amerikansk innhold:	Ja

Table 1/2

Katalognummer	Armeringstørrelse, metrisk	Armeringstr., US	Armeringsjern, Canada	Diameter 1 (Ø1)	Diameter 2 (Ø2)	Lengde 1 (L1)
RBT1114101A	43 mm, 36 mm	#14, #11	45M., 35M	70 mm	52 mm	152 mm
RBT1418101A	57 mm, 43 mm	#18, #14	55M., 45M	86 mm	67 mm	165 mm

Table 2/2

Katalognummer	Lengde 2 (L2)	Vekt på enhet
---------------	---------------	---------------


RBT1114101A	76 mm	2.19 kg
RBT1418101A	76 mm	3.55 kg

YTTERLIGERE PRODUKTDETALJER

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMMER

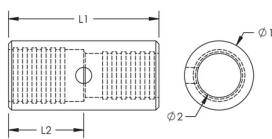

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

Nord-Amerika

+1.800.753.9221
Alternativ 1 –
Kundeservice
Alternativ 2 – Teknisk
støtte

Europa

Nederland:
+31 800-0200135
Frankrike:
+33 800 901 793

Europa

Tyskland:
800 1890272
Andre land:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE