


Front Panel, Front Anodized, Rear Conductive, Shielded, Side Hinged, 6 U, 84 HP

Power Utilities

KATALOGNUMMER

20848-617

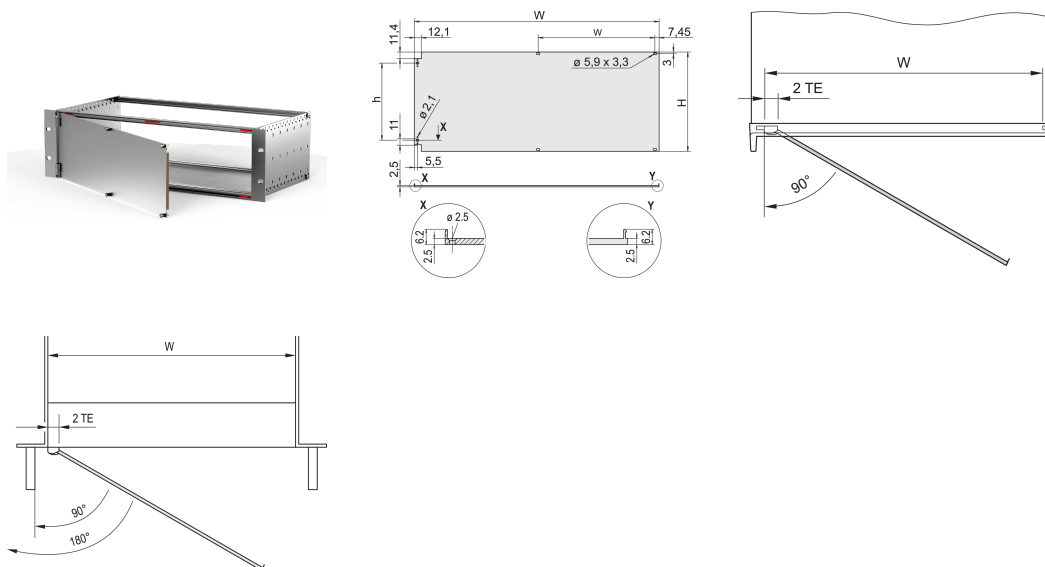

Front panel with textile EMC gasket, side hinged assembly.

SERTIFISERINGER



FUNKSJONER

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases

Hinges can be fitted on left or right

PRODUKTEGENSKAPER

Produkttype: Frontpanel

Type: Frontpanel uten håndtak

Montering: Hengslet, side

EMC-skjerming: Nei (ettermonterbar)

Pakning: Textile

Materiale: Aluminium

Front finish: Eloksert

Bakutførelse: Ledende

Behandlede kanter: Nei

Rackhøyde: 6 U

Høyde: 261.8 mm

Rackbredde: 84 HP

Bredde: 426.4 mm

Pakkeantall: 1

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE