
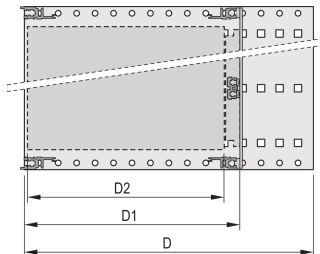
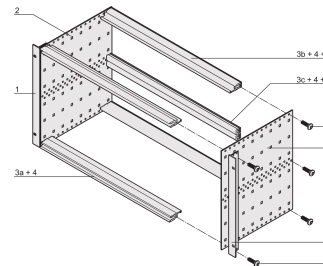


EuropacPRO 19" Subrack Kit for Backplane, Slide Rail, 3 U, 355 mm

Power Utilities

KATALOGNUMMER

24553-134

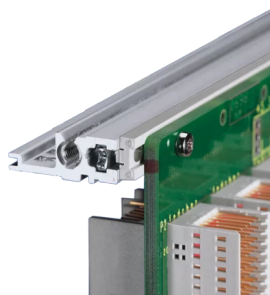

Non-shielded subrack for backplane, subrack can be assembled on slide rails to support the subrack inside a cabinet.

SERTIFISERINGER



FUNKSJONER

Subrack with side panel type F ("Flexible"), 19" bracket is depth-adjustable

Subrack can be used with slide rails

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 11 kg

Threaded insert, insulation strip pre-fitted

PRODUKTEGENSKAPER

Produkttype: Subrack/chassis

Rackhøyde: 3 U

Rackbredde: 84 HP

Dybde: 355 mm

For montering: Bakplan

Styredybde: 160 mm; 220 mm; 280 mm; 340 mm

EMC-skjerming: Nei

Pakning: Rustfritt stål

Statisk belastning: 11 kgf

Håndtak inkludert: Nei

Montering: Rack

Samsvarer med: IEC 60297-3-103

Pakkeantall: 1

YTTERLIGERE PRODUKTDETALJER

Alternative product for older EuropacLab and Europac subrack series.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE