
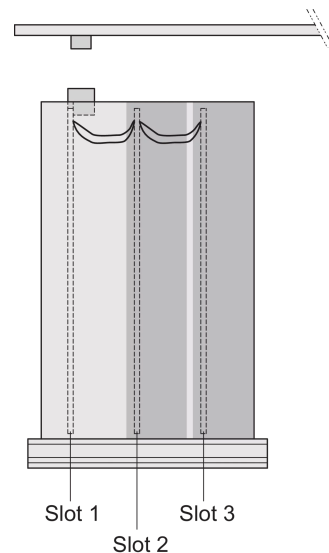
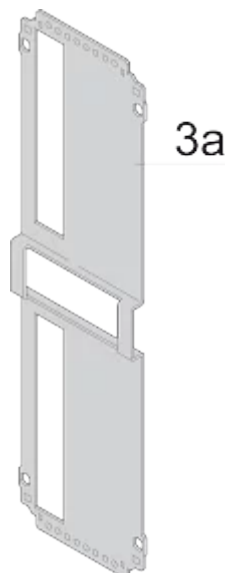
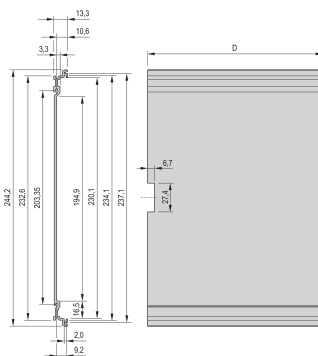
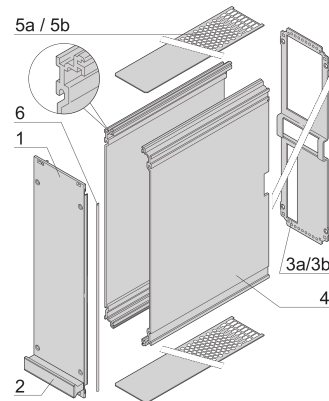


**Frame Type Plug-In Unit PRO Kit, Shielded,
Plain Cover, 1 Connector, 6 U, 10 HP, 227 mm**

Power Utilities

KATALOGNUMMER

24813-960

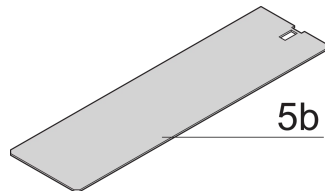

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats; with plain covers; rear panel with one cutout for one connector.



FUNKSJONER

Rear panel with cut-out for single connector (conforms to EN 60603, DIN 41612, construction types: B, C, D, F, H, Q, R, S)

Extruded side panels with groove to right and left, to insert a PCB (board position in accordance with standard in left side panel only)

Plain cover plates

PRODUKTEGENSKAPER

Produkttype: Kasset

Type: Frame type Plug-in Units PRO

Håndtakstype: Trapesform

Rackhøyde: 6 U

Rackbredde: 10 HP

Dybde: 227 mm

EMC-skjerming: Ja

Pakning: Textile

Type bakpanel: Enkel kobling utkobling

Type dekselplate: Dekkplate uten perforering

Materiale: Aluminium

Front finish: Elokstert

Bakutførelse: Elokstert

YTTERLIGERE PRODUKTDETALJER

Guide rails, 2 rear panel retainers and PCB fixing for slot 1 and one slot 2 are already included. Where additional PCBs without rearward connectors are to be fitted, guide rail (part no. 24812-101) and 'PCB fixing from slot 2' (part no. 24812-301 + screw, part no. 24560-178) are also required.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE