


Front Panel Alternative for Combined Mounting, U-profile, Textile, 6 U, 2 HP

Power Utilities

KATALOGNUMMER

30849-140

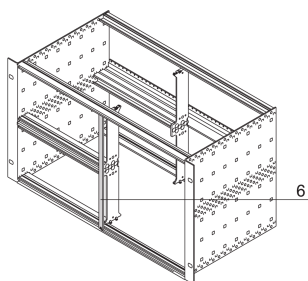

The 2 HP wide front panel covers an open slot. The U-profile front panel can be combined with a textile EMC gasket. It be fixed with screws and washers. Due to the 2 HP width no sleeves can be used.

SERTIFISERINGER



FUNKSJONER

U-profile front panel 6 U, 2 HP, Al, 2.5 mm

Prepared for textile EMC gasket

PRODUKTEGENSKAPER

Produkttype: Frontpanel

Front finish: Eloksert

Bakutførelse: Ledende

Behandlede kanter: Nei

Rackhøyde: 6 U

Pakkeantall: 5

YTTERLIGERE PRODUKTDETALJER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE