


U-profile Front Panel, Shieldable, D-Sub Cutouts, 3 U, 4 HP, 1 x 9 Pin

Power Utilities

KATALOGNUMMER

30849-749

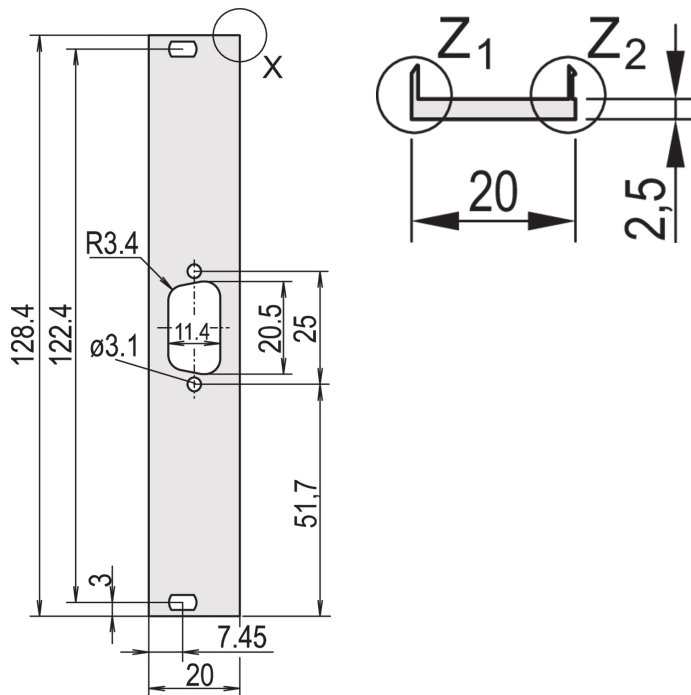

U-profile front panel with cutout for D-Sub connectors. Shieldable for textile EMC gasket.

SERTIFISERINGER



FUNKSJONER

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

PRODUKTEGENSKAPER

Produkttype: Frontpanel

Type: Frontpanel uten håndtak

Montering: Skrue foran

EMC-skjerming: Nei (ettermonterbar)

Pakning: Textile

Materiale: Aluminium

Front finish: Eloksert

Bakutførelse: Ledende

Behandlede kanter: Nei

Rackhøyde: 3 U

Høyde: 128.4 mm

Rackbredde: 4 HP

Bredde: 20 mm

Samsvarer med: IEC 60297-3-101; IEEE 1101.1/10

Pakkeantall: 5

YTTERLIGERE PRODUKTDETALJER

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE