


# Front Panel 2 HP Wide for Combined Mounting

## Strømforsyning

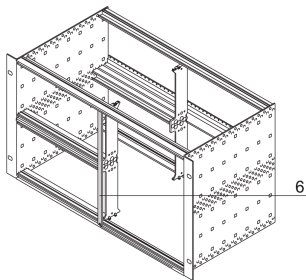

The 2 HP wide front panel covers an open slot. The non-shielded version can be fixed with screws and washers. Due to the 2 HP width, no sleeves can be used.

## SERTIFISERINGER



## FUNKSJONER

Flat front panel 6 U, 2 HP, Al, 2.5 mm

## SPESIFIKASJONER

| Table 1/1     |              |             |               |             |                  |
|---------------|--------------|-------------|---------------|-------------|------------------|
| Katalognummer | Front Finish | Rear Finish | Treated Edges | Rack Height | Package Quantity |
| 30847-472     | Anodized     | Conductive  | Nei           | 6 U         | 5                |

## ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVARSEL

---

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på [www.nvent.com](http://www.nvent.com) og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlatelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**