


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Strømforsyning

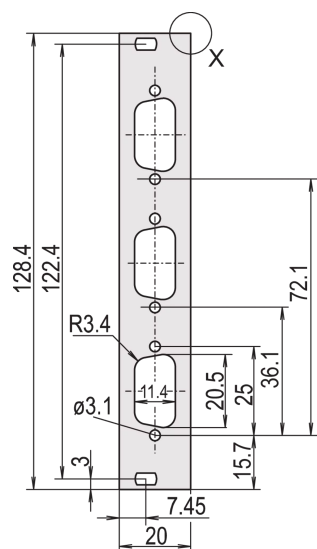

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

SERTIFISERINGER



FUNKSJONER

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

SPESIFIKASJONER

Table 1/3

Katalognummer	Package Quantity	Montering	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
---------------	------------------	-----------	-----------------	--------------	-------------	---------------

30118-348	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei
30118-349	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei
30118-350	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei
30118-351	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei
30118-352	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei
30118-353	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei
30118-354	5	Screw-on Front	Rustfritt stål	Anodized	Conductive	Nei

Table 2/3						
Katalognummer	Samsvarer med	EMC Shielding	Høyde	Materiell	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U

Table 3/3			
Katalognummer	Rack Width	Type	Bredde

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmaterieil.

Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlattelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE