


Front Panel, Flat, Unshielded, D-Sub Cutouts

Strømforsyning

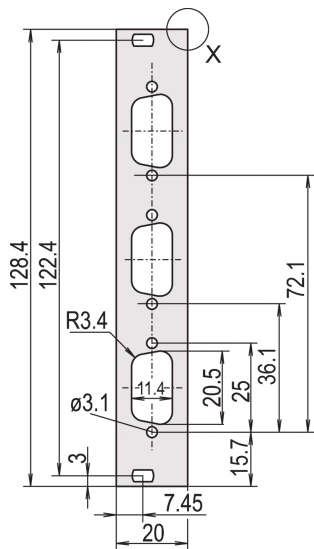

Flat front panel with cutout for D-Sub connectors.
Unshielded version.

SERTIFISERINGER



FUNKSJONER

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

SPESIFIKASJONER

Table 1/3						
Katalognumme r	Package Quantity	Montering	Front Finish	Rear Finish	Treated Edges	Samsvarer med
30118-341	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3- 101, IEEE 1101.1/10

Katalognummer	Package Quantity	Montering	Front Finish	Rear Finish	Treated Edges	Samsvarer med
30118-342	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10
30118-343	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10
30118-344	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10
30118-345	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10
30118-346	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10
30118-347	5	Screw-on Front	Anodized	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Katalognummer	EMC Shielding	Høyde	Materiell	Product Type	Rack Height	Rack Width
30118-341	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-342	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-343	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-344	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-345	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-346	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-347	Nei	128.4 mm	Aluminium	Front Panel	3 U	4 HP

Table 3/3

Katalognummer	Type	Bredde
30118-341	Front Panel without Handle	20 mm

Katalognummer	Type	Bredde
30118-342	Front Panel without Handle	20 mm
30118-343	Front Panel without Handle	20 mm
30118-344	Front Panel without Handle	20 mm
30118-345	Front Panel without Handle	20 mm
30118-346	Front Panel without Handle	20 mm
30118-347	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlattelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE