


Front Panel, Shielded, Bottom Hinged

Strømforsyning

U-profile front panel bottom hinged for textile gasket.

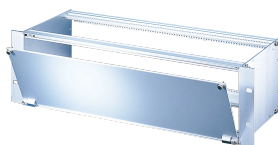

SERTIFISERINGER



FUNKSJONER

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPESIFIKASJONER

Table 1/3

Katalognummer	Rack Height	Rack Width	Package Quantity	Montering	EMC Gasket Type	Front Finish
20848-599	3 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-600	3 U	63 HP	1	Hinged, Bottom	Textile	Anodized

Katalognummer	Rack Height	Rack Width	Package Quantity	Montering	EMC Gasket Type	Front Finish
20848-601	3 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-602	6 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-603	6 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-604	6 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-605	4 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-606	4 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-607	4 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-608	3 U	28 HP	1	Hinged, Bottom	Textile	Anodized
20848-696	6 U	28 HP	1	Hinged, Bottom	Textile	Anodized

Table 2/3

Katalognummer	Rear Finish	Treated Edges	Samsvarer med	EMC Shielding	Høyde	Materiell
20848-599	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium
20848-600	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium
20848-601	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium
20848-602	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Aluminium
20848-603	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Aluminium
20848-604	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Aluminium

Katalognummer	Rear Finish	Treated Edges	Samsvarer med	EMC Shielding	Høyde	Materiell
20848-605	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Aluminium
20848-606	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Aluminium
20848-607	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Aluminium
20848-608	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium
20848-696	Conductive	Nei	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Aluminium

Table 3/3

Katalognummer	Product Type	Type	Bredde
20848-599	Front Panel	Front Panel without Handle	213 mm
20848-600	Front Panel	Front Panel without Handle	319.7 mm
20848-601	Front Panel	Front Panel without Handle	426.4 mm
20848-602	Front Panel	Front Panel without Handle	213 mm
20848-603	Front Panel	Front Panel without Handle	319.7 mm
20848-604	Front Panel	Front Panel without Handle	426.4 mm
20848-605	Front Panel	Front Panel without Handle	213 mm
20848-606	Front Panel	Front Panel without Handle	319.7 mm
20848-607	Front Panel	Front Panel without Handle	426.4 mm
20848-608	Front Panel	Front Panel without Handle	141.9 mm

Katalognummer	Product Type	Type	Bredde
20848-696	Front Panel	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlatelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE