


Front Panel, Unshielded, Bottom Hinged

Strømforsyning

Unshielded front panel bottom hinged.

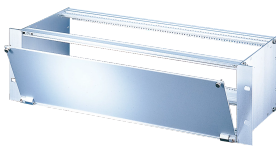

SERTIFISERINGER



FUNKSJONER

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPESIFIKASJONER

Table 1/3

Katalognummer	Rack Height	Rack Width	Package Quantity	Montering	Front Finish	Rear Finish
20838-271	3 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-272	3 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3 U	84 HP	1	Hinged, Bottom	Anodized	Conductive

Katalognummer	Rack Height	Rack Width	Package Quantity	Montering	Front Finish	Rear Finish
20838-274	6 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-277	4 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-280	3 U	28 HP	1	Hinged, Bottom	Anodized	Conductive

Table 2/3

Katalognummer	Treated Edges	Samsvarer med	EMC Shielding	Høyde	Materiell	Product Type
20838-271	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	128.4 mm	Aluminium	Front Panel
20838-272	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	128.4 mm	Aluminium	Front Panel
20838-273	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	128.4 mm	Aluminium	Front Panel
20838-274	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	261.8 mm	Aluminium	Front Panel
20838-275	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	261.8 mm	Aluminium	Front Panel
20838-276	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	261.8 mm	Aluminium	Front Panel
20838-277	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	172.9 mm	Aluminium	Front Panel

Katalognummer	Treated Edges	Samsvarer med	EMC Shielding	Høyde	Materiell	Product Type
20838-278	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	172.9 mm	Aluminium	Front Panel
20838-279	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	172.9 mm	Aluminium	Front Panel
20838-280	Nei	IEC 60297-3-101, IEEE 1101.1/10	Nei	128.4 mm	Aluminium	Front Panel

Table 3/3

Katalognummer	Type	Bredde
20838-271	Front Panel without Handle	213 mm
20838-272	Front Panel without Handle	319.7 mm
20838-273	Front Panel without Handle	426.4 mm
20838-274	Front Panel without Handle	213 mm
20838-275	Front Panel without Handle	319.7 mm
20838-276	Front Panel without Handle	426.4 mm
20838-277	Front Panel without Handle	213 mm
20838-278	Front Panel without Handle	319.7 mm
20838-279	Front Panel without Handle	426.4 mm
20838-280	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlatelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE