


Novastar Glass Door, 180° Opening Angle

Strømforsyning

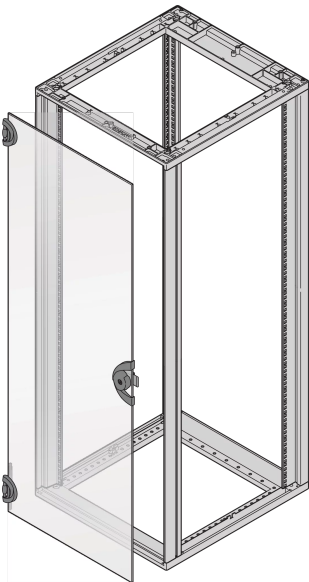

Glazed / Glass doors for aluminum frame cabinets with attractive design, ideally suited for general electronics, test & measurement, audio/video and broadcasting applications.

SERTIFISERINGER



FUNKSJONER

Glass type: ESG 6 mm, EN 12150

Opening angle 180°

Lock with key

Can be assembled at front and rear

SPESIFIKASJONER

Table 1/2

Katalognummer	Rack Height	Høyde	Bredde	Farge	Color Code	Product Type
27230-001	6 U	323 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-002	9 U	422 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-003	12 U	555 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-004	16 U	733 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-005	20 U	911 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-006	25 U	1133 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-028	29 U	1345 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-007	34 U	1534 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-008	38 U	1711 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-009	43 U	1933 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-010	47 U	2111 mm	553 mm	Light Grey	RAL 7035	Cabinet Door

Table 2/2

Katalognummer	Type
27230-001	Glass Door
27230-002	Glass Door
27230-003	Glass Door
27230-004	Glass Door
27230-005	Glass Door

Katalognummer	Type
27230-006	Glass Door
27230-028	Glass Door
27230-007	Glass Door
27230-008	Glass Door
27230-009	Glass Door
27230-010	Glass Door

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlattelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE