


PSU 19" for CompactPCI, AC/DC, 6 U, 8 HP

KATALOGNUMMER

13100-145

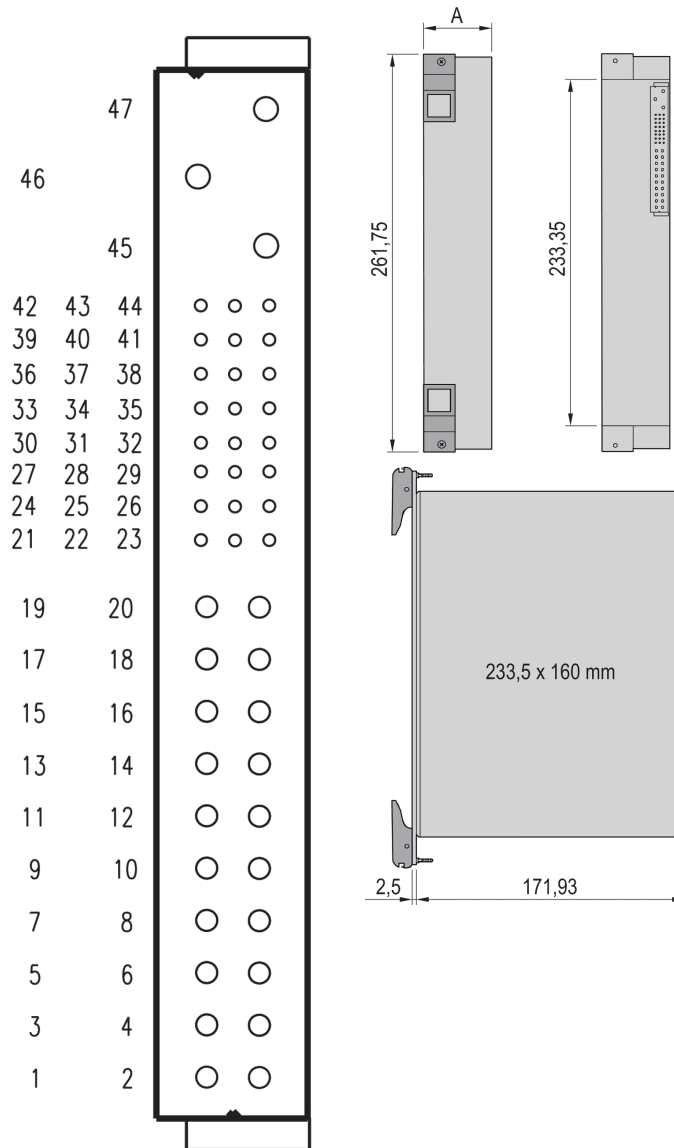

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

SERTIFISERINGER



FUNKSJONER

Connector P47 and CompactPCI signalling

4 output voltages

Redundant operation with Current Share Bus (CSB), hot-swap

PRODUKTEGENSKAPER

Produkttype: Strømforsyning

Type: 19-tommers vekslemodus

Fungerer med: CompactPCI og VME64x

Inngangsspenning AC: 90 – 264V

Effekt: 500W

Antall utgangsspenninger: 4

Spennings 1: 5V

Strøm 1: 50A

Spennings 2: 3.3V

Strøm 2: 60A

Spennings 3: 12V

Strøm 3: 12A

Spennings 4: -12V

Strøm 4: 4A

Rackhøyde: 6U

Rackbredde: 8HP

Dybde: 171.93mm

Antall pakker: 1

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE