


PXI-Express System, 4 U, 8 slots, Gen 3

KATALOGNUMMER

14579-030

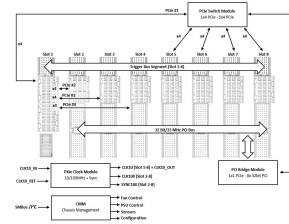

Desktop PXI Express Chassis for one PXI Express System Controller with up to 16 HP and 7 PXI or PXI Express Boards with 4 HP Width.

SERTIFISERINGER



FUNKSJONER

PXI Express Desktop Chassis, 4 U, 44 HP

1 PXIe System Slot an 7 Hybrid Slots

Ultra-high performance Gen 3 PCIe switching with a default four-link (4x4) System Slot

Powerful cooling concept with low fan noise, 50 W per slot @ 15K temperature increase

Air flow from bottom to rear with temperature controlled fans; Integrated Chassis Monitoring Modul (CMM)

Wide range AC input with mains switch on the rear side, power push button on the front (top)

Rear panel external 10 MHz clock inputs/outputs

PRODUKTEGENSKAPER

Produkttype: System

Antall spor: 8

Type: Skrivebord

Bakplantype: PXI Express, 4-koblingskonfigurasjon

Dataoverføring: PCIe Gen3

Strøm per spor: 50W

Inngangsspenning AC: 100 – 240V

Luftstrømretning: Bunn til bakside

Rackhøyde: 4U

Strømforsyningstype: Åpen ramme

Strømforsyning inkludert: Ja

Bakre i/U: Nei

Samsvarer med: PXISA PXI-5 R1.1

Antall tidsspor for PXI Express: 0

Dybde: 315mm

Antall pakker: 1

YTTERLIGERE PRODUKTDETALJER

System in accordance with IEC 60297--3--101, --102, --103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG rev. 3.0 and PXI-5.

Modified systems available on request.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieil. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE