


EuropacPRO 19" Subrack Kit for Railway, Shielded, EN 50155, 6 U, 84 HP, 235 mm

KATALOGNUMMER

21500-080

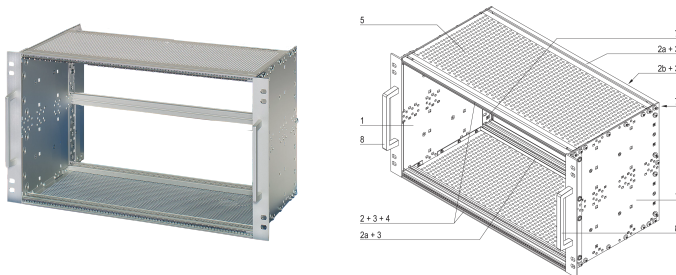

Subrack for Railway applications, conform to EN50155 standard, shielded versions.

SERTIFISERINGER



FUNKSJONER

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Aluminum construction

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

PRODUKTEGENSKAPER

Rackhøyde: 6U

Antall pakker: 1

For montering: Sentralenhet

Kortdybde: 220mm

EMC-pakningstype: Tekstil

Støt- og vibrasjonstoleranse: 5g (force)

Håndtak inkludert: Ja

Montering: Stativ

Samsvarer med: IEC 60297-3-103; EN 50155 del 12.2.11

Dybde: 235mm

EMC-beskyttelse: Ja

Overflate: Anodisert, Passivert

Materiale: Aluminium

Produkttype: Delrack/chassis

Rackbredde: 84HP

Statisk belastning: 15kg

YTTERLIGERE PRODUKTDETALJER

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE