
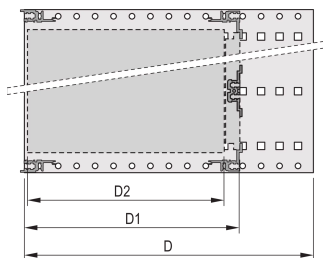
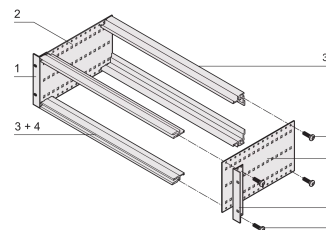


EuropacPRO 19" Subrack Kit for DIN Connector, Retrofit Shielding, 3 U, 355 mm

KATALOGNUMMER

24563-194

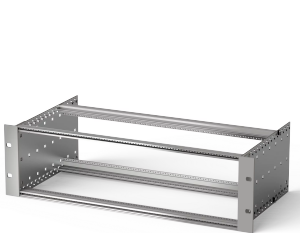

Non-shielded subrack for Din Connector mounting EN 60603-2 (DIN 41612).

SERTIFISERINGER



FUNKSJONER

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Aluminum construction

IP 20, in accordance with IEC 60529

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rails for connector mounting (IEC 60603-2 / DIN 41612)

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Horizontal rail type "light"

PRODUKTEGENSKAPER

Rackhøyde: 3U

Dybde: 355mm

Antall pakker: 1

For montering: DIN-kontakt

Kortdybde: 160mm; 220mm; 280mm; 340mm

EMC-pakningstype: Rustfritt stål (kan monteres i ettertid)

Håndtak inkludert: Nei

Montering: Stativ

Samsvarer med: IEC 60297-3-103

EMC-beskyttelse: Nei

Overflate: Anodisert; Passivert

Materiale: Aluminium

Produkttype: Delrack/chassis

Rackbredde: 84HP

Statisk belastning: 11kg

YTTERLIGERE PRODUKTDETALJER

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE