


Plug-In Unit U-Profile Front Panel for IEL, IET, Type 2, 3 U, 12 HP, 0.1" Offset, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGNUMMER

30848-432

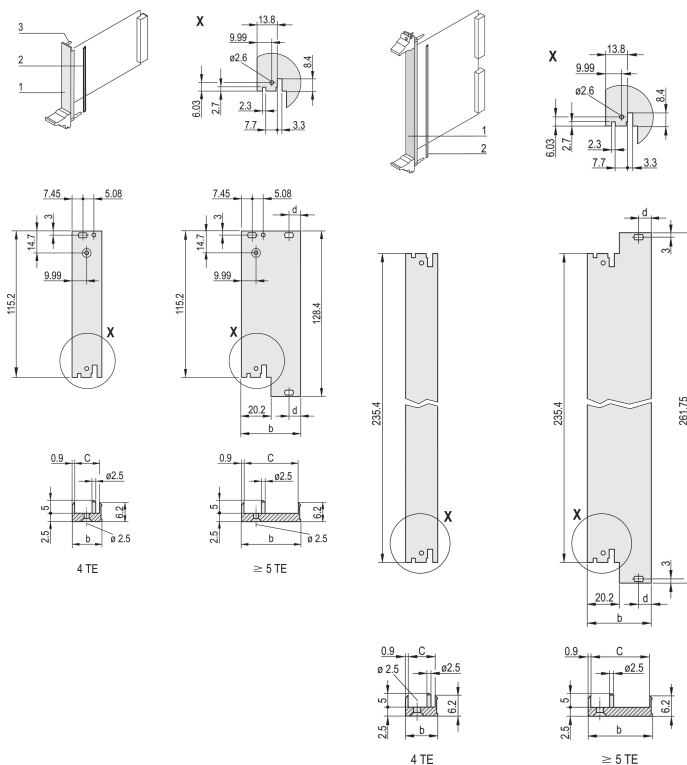

U-Profile front panel can be shielded with a textile gasket. It can be combined with the IEL and IET or the type 2 handle in trapezoid form, PCB mounting = 0,1" offset.

SERTIFISERING



FUNKSJONER

Manufacturing process causes various surface structures to appear between 4 to 12 HP and 14 to 16 HP

Front panel, 3 U

Stainless steel alignment pin pressed-in

Al extrusion, 2.5 mm, front anodized, rear conductive

U-profile, shieldable with textile EMC gasket

For IEL/IET/Trapeziform Type 2 handle

For front mounting, PCB fixing with 0.1" offset

PRODUKTEGENSKAPER

Rackbredde: 12HP

Antall pakker: 1

Tilbehørstype: Frontpanel

Håndtakstype: IEL; IET

Montering: Front som skrues på med 0,1-tommers forskyvning

EMC-pakningstype: Tekstil

Fremre overflate: Anodisert

Bakre flate: Strømledende

Behandlede kanter: Nei

Samsvarer med: IEC 60297-3-102; IEEE 1101,10; IEC 60297-3-103; IEEE 1101,1/11

Dybde: 2.5mm

EMC-beskyttelse: Nei (kan monteres etterpå)

Overflate: Anodisert; Passivert

Høyde: 128.4mm

Materiale: Aluminium

Produkttype: Frontpanel

Rackhøyde: 3U

Type: Frontpanel for håndtak (PIU)

Bredde: 60.6mm

YTTERLIGERE PRODUKTDETALJER

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieill. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE