


Horizontal skinne foran, type H-KD, tung, kort leppe, 1000 mm

KATALOGNUMMER

34560-201

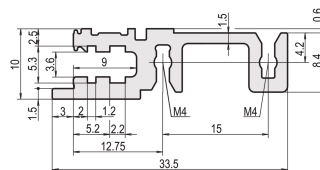

Combinations of horizontal rails and side panels

	Side panel	Light x L	Fluorescent F	Heavy x L	Rugged x L
Heavy x L	+	+	+	+	+
Heavy x R	+	+	+	+	+
Light x L	+	+	+	+	+
Fluorescent F	+	+	+	+	+
Heavy x L	+	+	+	+	+
Rugged x L	+	+	+	+	+

Legend: "+" can be combined, "-" combination not recommended

Aluminum extrusion horizontal rail of the type H-KD (H-KD = Heavy, Short Lip) with a anodized surface and conductive contact surface. Printed HP markings for a quick optical positioning of the guide rails. Suitable for RatiopacPRO/-AIR and EuropacPRO/-rugged).

SERTIFISERINGER



FUNKSJONER

Installation at top and bottom

Short lip (H-KD)

Aluminum extrusion, anodized finish, conductive contact surface

PRODUKTEGENSKAPER

Rackbredde: 195HP

Antall pakker: 1

Overflate: Anodisert

Lengde: 1000mm

Materiale: Aluminium

Produktserie: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Produkttype: Horisontal skinne

Type: Tungt, KD

Fungerer med: Delrack; Esker

YTTERLIGERE PRODUKTDETALJER

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE