


Socket Strip, SCHUKO/UTE, Local Display, 6 x SCHUKO/UTE Outlets

KATALOGNUMMER

60110-294

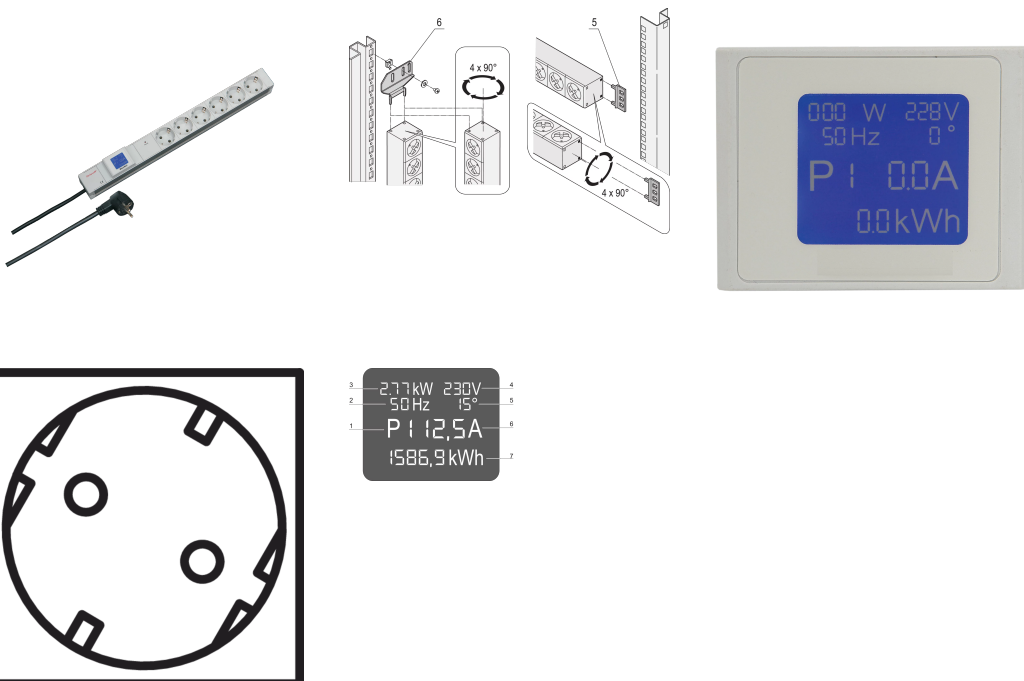

PDU with local power meter. Relevant Power data are shown on an integrated display.

SERTIFISERINGER



FUNKSJONER

Integrated measurement and display via local display unit

Socket strips with Schuko sockets

Mounting height 1 U

Socket strips can be rotated through all four directions (in 90° increments) during installation

Horizontal and vertical mounting

Measurement functions: Voltage, Current, Power, Frequency, cos phi

PRODUKTEGENSKAPER

Produkttype: Sokkelskinne

Kontakttype: SCHUKO

Antall kontakter: 6

Farge: Grå

Utganger med bryter: Nei

Lengde: 438.5mm

Spenning AC: 230V

Dybde: 44mm

Overflate: Anodisert

Materiale: Aluminium; Polyamid

Antall pakker: 1

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE