


EuropacPRO Rear Angle for Textile EMC Gasket

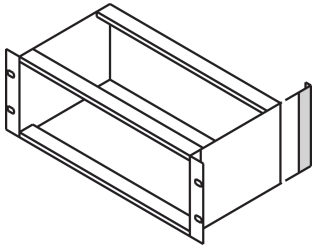

EuropacPro rear angle for Textile EMC Gasket, out of Aluminum extrusion with etched surface. Rear hood cannot be mounted simultaneously.

SERTIFISERINGER



FUNKSJONER

Required for rear shielding

Also useable at the front if you use a depth-adjustable 19" support bracket

SPESIFIKASJONER

- Materiale:** Aluminium
Produkttype: Deksel
Produktserie: EuropacPRO
Type: Bakre vinkel
Fungerer med: Delrack

Table 1/1

Katalognummer	Rackhøyde	Antall pakker	Høyde	Pakkeenhet	Hurtiglevering
24564-199	3U	2	132.6mm	Par	Nei
24564-799	9U	2	399.3mm	Par	Nei
24564-299	4U	2	177mm	Par	Nei

Katalognummer	Rackhøyde	Antall pakker	Høyde	Pakkeenhet	Hurtiglevering
24564-499	6U	2	265.9mm	Par	Nei

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmaterieil. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE