


Interscale Fan Holder With Fans

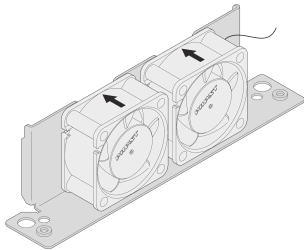

Interscale Fan Holder With Fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m³/h.

FUNKSJONER

Fan holder for mounting on bottom of case

Fans are simple to fit to the fan holder using vibration-damping fixing material

Fan holders fix into desktop case with 2 plastic feet or into 19" case with 2 screws

Fan holder cannot be used in conjunction with the mounting plate (instead use mounting plate with integrated fan holder)

For technical data of fans, please see delivery includes

SPESIFIKASJONER

Overflate:	Belagt med aluminiumsink
Type:	Viftebrett
Produkttype:	Vifteenhet
Inngangsspenning DC:	12V min

Table 1/2

Katalognummer	Bredde	Dybde	Antall pakker	Maks. statisk trykk	Maks. omgivelsestemperatur	Luftstrøm
24828-104	40mm	20mm	1		70°C	10m ³ /h
24828-105	40mm	20mm	1		70°C	10m ³ /h
24828-107	40mm	20mm	1		70°C	10m ³ /h

Katalognummer	Bredde	Dybde	Antall pakker	Maks. statisk trykk	Maks. omgivelsestemperatur	Luftstrøm
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-307	119mm	25mm	1		70°C	170m³/h
24830-101	80mm	25mm	1	95.41Pa	70°C	109m³/h
24830-102	80mm	25mm	1			

Table 2/2

Katalognummer	Støynivå	Høyde	Materiale	Effekt	Produktserie	Hurtiglevering
24828-104	18dB(A)	40mm	Stål	0.9W	Interscale	Nei
24828-105	18dB(A)	40mm	Stål	0.9W	Interscale	Nei
24828-107	18dB(A)	40mm	Stål	0.9W	Interscale	Nei
24828-204	32dB(A)	80mm	Stål	2W	Interscale	Nei
24828-205	32dB(A)	80mm	Stål	2W	Interscale	Nei
24828-207	32dB(A)	80mm	Stål	2W	Interscale	Nei
24828-305	43dB(A)	119mm	Stål	5.3W	Interscale	Nei
24828-307	43dB(A)	119mm	Stål	5.3W	Interscale	Nei
24830-101	44.62dB(A)	80mm	Stål			Nei

Katalognummer	Støynivå	Høyde	Materiale	Effekt	Produktserie	Hurtiglevering
24830-102		80mm	Stål			Nei

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE