

Static Handle Plastic in Trapezoid Form, Black



The static plastic handle, trapezoid form in black color can be mounted to a front panel for extraction of the PCB.

SERTIFISERINGER



FUNKSJONER

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPESIFIKASJONER

Fungerer med:	Frontpaneler
Produkttype:	Håndtak
Materiale:	Polykarbonat
Type:	Statisk

Table 1/2

Katalognummer	Rackbredde	Antall pakker	Håndtakstype	Antennbarhetsvurdering	Farge	Samsvarer med
20808-080	5HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-081	6HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-082	7HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-083	8HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-084	9HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-085	10HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-086	12HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-087	14HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-088	21HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-089	28HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-090	40HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Katalognummer	Rackbredde	Antall pakker	Håndtakstype	Antennbarhets vurdering	Farge	Samsvarer med
20808-091	42HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-396	3HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-397	4HP	1	Trapesformet, statisk	UL® 94V-0	Svart	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Table 2/2

Katalognummer	Bredde (W)	Hurtiglevering
20808-080	24mm	Nei
20808-081	29mm	Nei
20808-082	34.1mm	Nei
20808-083	39.2mm	Nei
20808-084	44.3mm	Nei
20808-085	49.4mm	Nei
20808-086	59.6mm	Nei
20808-087	69.7mm	Nei
20808-088	105.2mm	Nei
20808-089	140.8mm	Nei
20808-090	201.8mm	Nei
20808-091	212mm	Nei


Katalognummer	Bredde (W)	Hurtiglevering
20809-396	13.8mm	Nei
20809-397	18.9mm	Nei

YTTERLIGERE PRODUKTDETALJER

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

DIAGRAMMER

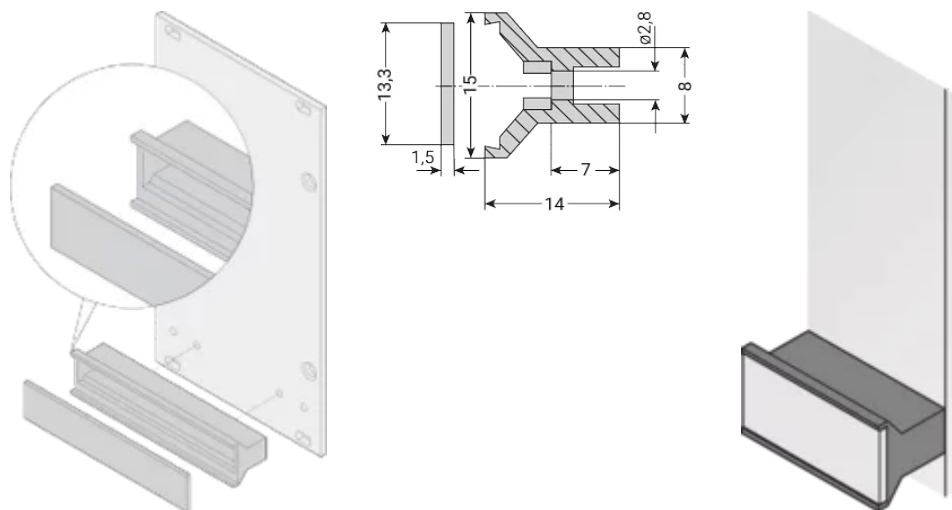

ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på www.nvent.com og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vår solide portefølje av merkevarer:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE