

Horizontal Pouring Basin, Side Fill, Extended



Extended side fill horizontal pouring basins are used when interferences of the structure will not allow top filling of the sleeve and the interferences are directly next to the tap hole in the sleeve.

FUNKCJE

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal side fill sleeves

SPECYFIKACJE

Material: Grafit

Table 1/1

Numer katalogowy	Średnica (Ø)	Długość 1 (L1)	Długość 2 (L2)	Szerokość (W)	Wysokość 1 (H1)	Wysokość 2 (H2)
RBHSA9750X	38 mm	248 mm	38 mm	76 mm	127mm	76mm
RBHSB10560X	38 mm	267 mm	38 mm	76 mm	152mm	76mm
RBHSB12065X	38 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSA9050D	54 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9050F	64 mm	229 mm	38 mm	76 mm	127mm	76mm
RBHSA9560M	95 mm	241 mm	38 mm	76 mm	152mm	76mm


Numer katalogowy	Średnica (Ø)	Długość 1 (L1)	Długość 2 (L2)	Szerokość (W)	Wysokość 1 (H1)	Wysokość 2 (H2)
RBHSB12065C	48 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065J	76 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB12065M	95 mm	305 mm	38 mm	76 mm	165mm	76mm
RBHSB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14065J	76 mm	356 mm	38 mm	76 mm	165mm	76mm
RBHSB14070D	54 mm	356 mm	38 mm	76 mm	178mm	76mm
RBHSB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBHSB16070F	64 mm	406 mm	38 mm	76 mm	178mm	76mm
RBHSB17070C	48 mm	432 mm	38 mm	76 mm	178mm	76mm
RBHSB177550 M	95 mm	451 mm	38 mm	76 mm	127mm	76mm
RBHSC23010M	95 mm	584 mm	38 mm	76 mm	254mm	76mm
RBHSC23075M	95 mm	584 mm	38 mm	76 mm	191mm	76mm
RBHSC30070D	54 mm	762 mm	38 mm	76 mm	191mm	76mm

DODATKOWE INFORMACJE O PRODUKCIE

RBHSA pouring basins require one RBW332 pouring basin frame and two RBS5000 bolt retainers. RBHSB pouring basins require one RBW3321 pouring basin frame and one RBS5000 bolt retainer. RBHSC pouring basins require one RBW3322 pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

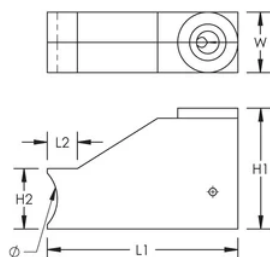

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

Ameryka Północna

+1.800.753.9221

Opcja 1 — obsługa klienta

Opcja 2 — wsparcie
techniczne

Europa

Niderlandy:

+31 800-0200135

Francja:

+33 800 901 793

Europa

Niemcy:

800 1890272

Inne kraje:

+31 13 5835404

APAC

Szanghaj:

+ 86 21 2412 1618/19

Sydney:

+61 2 975 185 00



Marki w naszej ofercie:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE