


19" Pusher Fan, 3 U, Axial

Instalacje zasilające

Fan tray with integrated pusher fan.

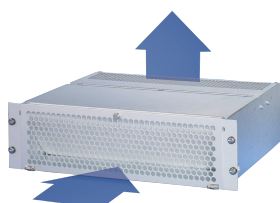

CERTYFIKATY



FUNKCJE

Ventilation directed accurately to the electronics

19" Pusher Fan, 3 U, Axial

Air infeed from front, air exits at the top rear of cabinet (guided upwards by cover plates or via hoses to rear and upwards)

Contact protection in accordance with DIN EN ISO 13857

OKREŚLENIU SPECYFIKACJI

Table 1/1

Numer katalogowy	Input Voltage AC
10713-546	230 V min
10713-547	115 V min

ADDITIONAL PRODUCT DETAILS

With cover plates, this pusher fan can be re-fitted to different cooling concepts

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE