


EuropacPRO 19" Subrack Kit for DIN Connector

Instalacje zasilające

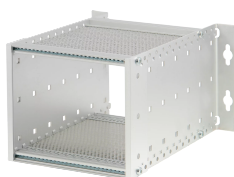

Subrack for assembly to a wall or cabinet panel for Din connector mounting without rear hood.

CERTYFIKATY



FUNKCJE

Subrack with side panel type L ("light")

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

For connector mounting (DIN 41612, EN 60602-3)

Horizontal rails type "light"

Aluminum construction

OKREŚLENIU SPECYFIKACJI

Table 1/2

Numer katalogowy	Product Type	Rack Height	Rack Width	Głębokość	For Mounting	Board Depth
------------------	--------------	-------------	------------	-----------	--------------	-------------

24563-109	Subrack/Chassis	3 U	28 HP	205 mm	DIN Connector	160 mm
-----------	-----------------	-----	-------	--------	---------------	--------

Table 2/2

Numer katalogowy	EMC Shielding	Obciążenie statyczne	Handle Included	Montaż	Zgodność z	Package Quantity
24563-109	Nie	2.5 kgf	Nie	Ściana	IEC 60297-3-103	1

ADDITIONAL PRODUCT DETAILS

EMC version on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE