


EuropacPRO 19" Subrack Kit for Power Distribution Module, Unshielded

Instalacje zasilające

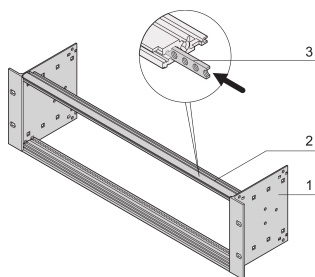

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted.

CERTYFIKATY



FUNKCJE

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted

Modular frame to accept e.g. power distribution modules

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Aluminium side panels

Horizontal rails type "light"

IEEE 1101.1 compatible

OKREŚLENIU SPECYFIKACJI

Table 1/2

Numer katalogowy	Product Type	Rack Height	Rack Width	Głębokość	For Mounting	EMC Shielding
------------------	--------------	-------------	------------	-----------	--------------	---------------

24563-100	Subrack/Chassis	3 U	84 HP	115 mm	Power Distribution Module	Nie
-----------	-----------------	-----	-------	--------	---------------------------	-----

Table 2/2

Numer katalogowy	Obciążenie statyczne	Handle Included	Montaż	Zgodność z	Package Quantity
24563-100	2.5 kgf	Nie	Rack	IEC 60297-3-103	1

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE