


EuropacPRO Rugged Rear Angle for Textile EMC Gasket

Instalacje zasilające

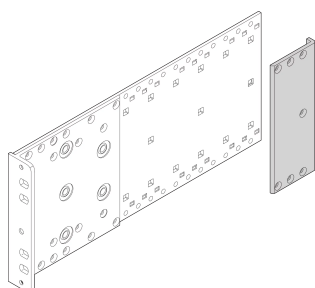

Corner profile covers the slot between the side panel and the rear panel of a subrack. Needed for a proper EMC shielding.

CERTYFIKATY



FUNKCJE

Required for shielding of rear

Can also be used as front closure when using a depth-adjustable 19" support bracket

OKREŚLENIU SPECYFIKACJI

Table 1/2

Numer katalogowy	Rack Height	Package Quantity	Wysokość	Product Family	Product Type	Typ
24566-499	6 U	1	265.9 mm	EuropacPRO	Pokrywa	Rugged
24566-197	3 U	1	132.6 mm	EuropacPRO	Pokrywa	Rugged

Numer katalogowy	Rack Height	Package Quantity	Wysokość	Product Family	Product Type	Typ
24566-199	3 U	1	132.6 mm	EuropacPRO	Pokrywa	Rugged
24566-497	6 U	1	265.9 mm	EuropacPRO	Pokrywa	Rugged

Table 2/2

Numer katalogowy	Works With	Jednostka opakowania	Certyfikaty
24566-499	Subracks	Para	RoHS
24566-197	Subracks	Para	
24566-199	Subracks	Para	RoHS
24566-497	Subracks	Para	

ADDITIONAL PRODUCT DETAILS

Please order EMC textile gasket separately.

Corner profile cannot be used together with adapter for rear mounting.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE