


U-profile Front Panel, Shieldable, D-Sub Cutouts

Instalacje zasilające

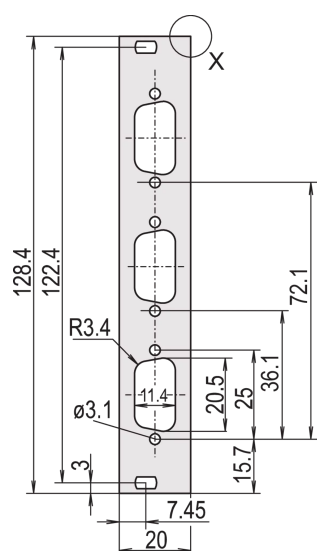

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTYFIKATY



FUNKCJE

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

OKREŚLENIU SPECYFIKACJI

Table 1/3

Numer katalogowy	Package Quantity	Montaż	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-749	5	Screw-on Front	Textile	Anodized	Conductive	Nie

Numer katalogowy	Package Quantity	Montaż	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
30849-750	5	Screw-on Front	Textile	Anodized	Conductive	Nie
30849-751	5	Screw-on Front	Textile	Anodized	Conductive	Nie
30849-752	5	Screw-on Front	Textile	Anodized	Conductive	Nie
30849-753	5	Screw-on Front	Textile	Anodized	Conductive	Nie
30849-754	5	Screw-on Front	Textile	Anodized	Conductive	Nie
30849-755	5	Screw-on Front	Textile	Anodized	Conductive	Nie

Table 2/3

Numer katalogowy	Zgodność z	EMC Shielding	Wysokość	Materiał	Product Type	Rack Height
30849-749	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-750	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-751	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-752	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-753	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-754	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30849-755	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U

Table 3/3

Numer katalogowy	Rack Width	Typ	Szerokość
------------------	------------	-----	-----------

30849-749	4 HP	Front Panel without Handle	20 mm
30849-750	4 HP	Front Panel without Handle	20 mm
30849-751	4 HP	Front Panel without Handle	20 mm
30849-752	4 HP	Front Panel without Handle	20 mm
30849-753	4 HP	Front Panel without Handle	20 mm
30849-754	4 HP	Front Panel without Handle	20 mm
30849-755	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE