


# ACS-30 Sensing and Monitoring Module

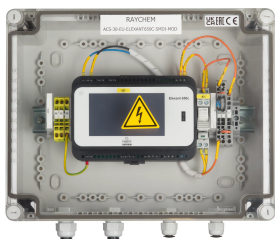

The nVent RAYCHEM ACS-30-EU-ELEXANT650C-SMDI-MOD Module for the ACS-30 system provides smart sensor input for surface snow melting and roof & gutter de-icing applications. The Remote Monitoring Module (RMM) is used to collect sensor/temperature inputs for monitoring of the heat tracing circuits of an ACS-30 control system.

## FUNKCJE

The output from the ACS-30-EU-ELEXANT650C-SMDI-MOD module enables the switching of the heating circuits within the power & control module (PCM)

The ACS-30-EU-ELEXANT650C-SMDI-MOD module provides ground or roof & gutter temperature and moisture sensing for the ACS-30 control system

Ground temperature and moisture sensor (E650C-G) and roof & gutter temperature and moisture sensor (E650C-R) are sold separately

The RMM provides up to 8 sensor inputs per module with feedback to the ACS-30-EU-UIT3 interface

A single twisted pair RS-485 cable connects up to 247 RMM units providing additional temperature monitoring sensor inputs

The RMM is remotely located adjacent to the desired measurement locations

The RMM comes in 2 versions: ACS-30-EU-RMM3 (230 V) and ACS-30-EU-RMM3-24VDC (24 V), both pre-installed inside a compact enclosure

## OKREŚLENIU SPECYFIKACJI

Table 1/2

Numer katalogowy	Nazwa pozycji	Głębokość	Wysokość	Housing Material	IP Rating	Montaż
2000003973	ACS-30-EU-ELEXANT650C-SMDI-MOD	132 mm	262 mm	Poliwęglan	IP20	Wall Mounted

Table 2/2

Numer katalogowy	Nazwa pozycji	Szerokość
------------------	---------------	-----------

2000003973	ACS-30-EU-ELEXANT650C-SMDI-MOD	332 mm
------------	--------------------------------	--------

## OSTRZEŻENIE

---

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie [www.nvent.com](http://www.nvent.com) oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

### **Ameryka Północna**

Tel +1.800.545.6258

Fax +1.800.527.5703

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

### **Europe, Middle East,**

#### **Africa**

Tel +32.16.213.511

Fax +32.16.213.604

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

### **Asia Pacific**

Tel +86.21.2412.1688

Fax +86.21.5426.3167

[cn.thermal.info@nvent.com](mailto:cn.thermal.info@nvent.com)

### **Ameryka Łacińska**

Tel +1.713.868.4800

Fax +1.713.868.2333

[thermal.info@nvent.com](mailto:thermal.info@nvent.com)

Our powerful portfolio of brands:

**RAYCHEM PYROTENAX TRACER NUHEAT**