


VME64x System, 8 U, 21 Slot, Open Frame PSU

NUMER KATALOGOWY

20836-820

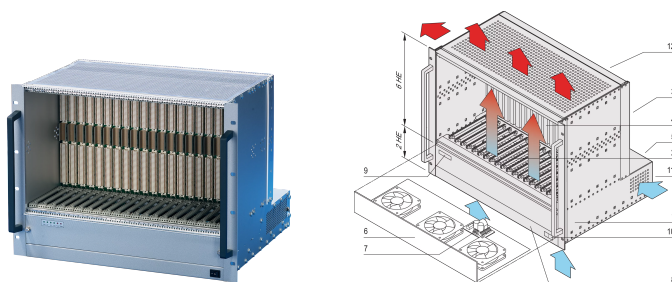

VME64 system for 21 VME64x boards 6 U, 160 mm. Rear I/O option The power for the system is supplied by a open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTYFIKATY



FUNKCJE

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 642 W (600 W at < 180 VAC)

Backplane VME64x 21 slot, 6 U, J1/J2 monolithic with P0 connector, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 3 fans, cooling from bottom to top; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep, Rear I / O option

Display module for DC operating voltages, fan and temperature alarm

ATRYBUTY PRODUKTU

Typ produktu: System

Liczba szczelin: 21

Typ: Montaż w stojaku 19"

Typ płyty montażowej: Rozszerzenie VME64 6 U

Transfer danych: VME64; VME2eSST

Moc na szczelinę: 30W

Napięcie wejściowe AC: 100 – 240V

Kierunek przepływu powietrza: Od dołu do góry

Wysokość stojaka: 8U

Typ zasilacza: Otwarta rama

Zasilacz w zestawie: Tak

Tylne We/Wy: Tak

Zgodność z: ANSI/VITA 1.1-1997

Głębokość: 412mm

Wysokość: 354.8mm

Szerokość: 449mm

Zasilanie: 600W

Liczba opakowań: 1

DODATKOWE INFORMACJE O PRODUKCIE

Modified systems available on request.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Marki w naszej ofercie:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE