


EuropacPRO 19" Subrack Kit for Backplane, Light, Unshielded, 3 U, 295 mm

NUMER KATALOGOWY

24564-133

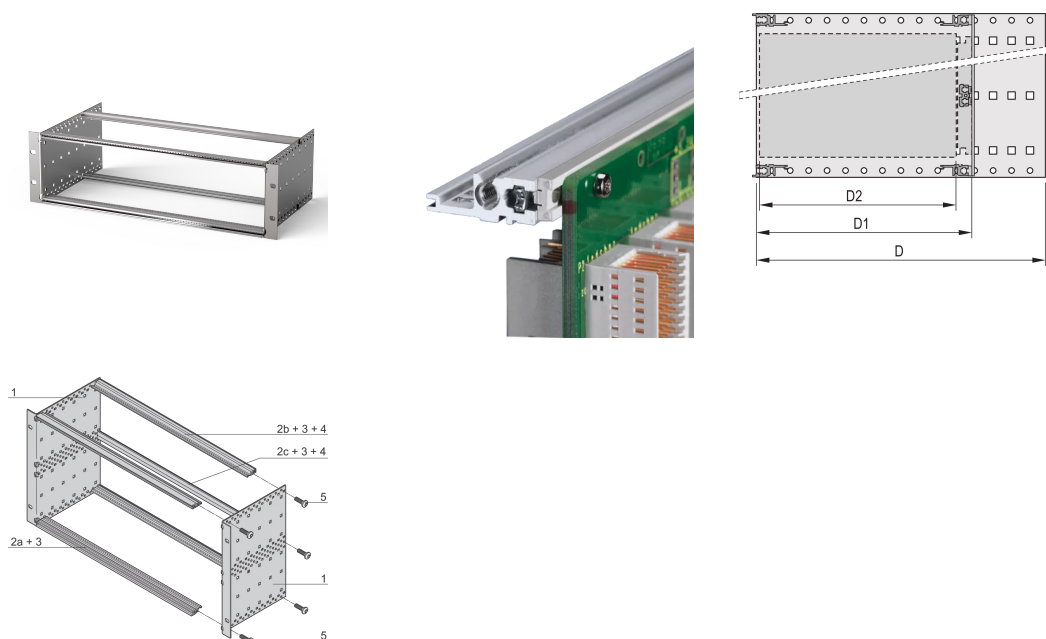

Non-EMC shielded subrack for backplane mounting, light version.

CERTYFIKATY



FUNKCJE

Subrack with side panel type L ("light") with integrated 19" support brackets

Horizontal rail type "light"

Aluminum construction

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 7.5 kg

Supplied as space-saving flat-pack

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Modifications such as cutouts, different finishes or dimensions available

ATRYBUTY PRODUKTU

Wysokość stojaka: 3U

Głębokość: 295mm

Liczba opakowań: 1

Do montażu: Płyta montażowa

Głębokość płyty: 160mm; 220mm; 280mm

Uchwyt w zestawie: Nie

Montaż: Stojak

Zgodność z: IEC 60297-3-100; IEC 60297-3-101; IEEE 1101.1

Ekranowanie EMC: Nie

Wykończenie: Anodyzowany; Powierzchnia pasywowana

Materiał: Aluminium

Typ produktu: Stojak podrzędny/podstawa montażowa

Szerokość stojaka: 84HP

Obciążenie statyczne: 7.5kg

DODATKOWE INFORMACJE O PRODUKCIE

Subrack is not prepared for shielding, retrofit for protection class IP 20 possible

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Marki w naszej ofercie:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE