


nVent CADDY Cat HP J-Hook with Shot-Fire Bracket

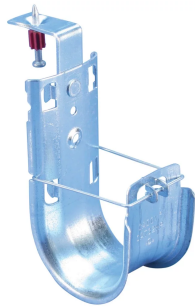

CARACTERÍSTICAS

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Complete with shot-fire bracket and pre-assembled drive pin from DEWALT®

Quickly and easily attaches to concrete, steel or composite metal decking

Integrated pin installs easily using powder-actuated or single-shot gas-actuated tools

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

ICC-ES ESR-2024 evaluation report available for drive pin from DEWALT®

ESPECIFICAÇÕES

Acabamento: Electrogalvanized; Pregalvanized

Material: Aço

Table 1/2

Número de catálogo	Número do artigo	Diâmetro (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6	Cable Capacity, Cat 6A
CAT16HPSF	181673	25 mm	690mm ²	20	15	10

Número de catálogo	Número do artigo	Diâmetro (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6	Cable Capacity, Cat 6A
CAT48HPSF	181676	75 mm	5974mm ²	200	150	80
CAT32HPSF	181675	50 mm	2561mm ²	90	60	35
CAT64HPSF	181677	100 mm	9987mm ²	330	220	140
CAT21HPSF	181674	33.3 mm	1174mm ²	50	40	25

Table 2/2

Número de catálogo	Número do artigo	Altura (H)	A	Static Load
CAT16HPSF	181673	120.7 mm	33 mm	270N
CAT48HPSF	181676	185.2 mm	33 mm	270N
CAT32HPSF	181675	139.7 mm	33 mm	270N
CAT64HPSF	181677	203.2 mm	33 mm	270N
CAT21HPSF	181674	130.2 mm	33 mm	270N


DETALHES ADICIONAIS DO PRODUTO

Uses Powers Fasteners, Inc. part number 50032.

Static load was established based on a 1" (25.4 mm) embedment depth and 3,000 psi (20.68 MPa) lightweight concrete. For variations in embedment and material please consult anchors.dewalt.com.

Pre-assembled drive pin from Powers Fasteners, Inc. works with Powers® C4CZ, Simpson® GCN-MEPKT, SPIT® P1000, P200, P2201, P3500 / PA3500, P35s, P45, P60, P7201, Sniper; Ramset® 721, Cobra, D45 / D60 / D60L, M70, SA270, T3SS, TS750P, TS60P, Viper; Hilti® DX35, DX350 / DX351 / DX36M, DX100 / DX200, DX460, DXA40, DXA41, DXE72 / DX400; Würth® Diva-1, BST-1, BST-2 or equivalent nailers.

DIAGRAMAS

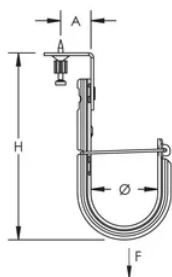

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência
técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

