

nVent CADDY Pyramid Universal Support



CARACTERÍSTICAS

Captive stainless steel nuts allow for custom attachment methods to the support base including easy attachment of stainless steel strut, threaded rod or other project-specific hardware

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Multiple sizes and load ratings offer the ability to tailor the solution to the application

Includes square holes for creating an H-Frame with a 12" (305 mm) cross support (PBU16 only)

Base is manufactured from UV-stabilized thermoplastic material

ESPECIFICAÇÕES

Static Load Safety Factor: 3:1

Temperatura: -45 to 65 °C

Table 1/3

Número de catálogo	Número do artigo	Material	Comprimento 1 (L1)	Comprimento 2 (L2)	Altura (H)	Largura (W)
PBU6	360488	Polyethylene, Polypropylene, Stainless Steel 18-8 (EN 1.4305)	139.7 mm	203 mm	101.6 mm	152 mm

Número de catálogo	Número do artigo	Material	Comprimento 1 (L1)	Comprimento 2 (L2)	Altura (H)	Largura (W)
PBU10	360489	Polyethylene, Polypropylene, Stainless Steel 18-8 (EN 1.4305)	254 mm	317.5 mm	101.6 mm	203 mm
PBU16	360490	Polyethylene, Polypropylene, Stainless Steel 18-8 (EN 1.4305)	406 mm	483 mm	101.6 mm	203 mm


Table 2/3

Número de catálogo	Número do artigo	Tamanho da rosca (TS)	Número de orifícios	A	B	Surface Area
PBU6	360488	3/8" UNC	3	114.3 mm	57.2 mm	26452mm ²
PBU10	360489	3/8" UNC	2	218.4 mm		59355mm ²
PBU16	360490	3/8" UNC	2	165.1 mm		91613mm ²

Table 3/3

Número de catálogo	Número do artigo	Static Load
PBU6	360488	1330N
PBU10	360489	4450N
PBU16	360490	6670N

DIAGRAMAS

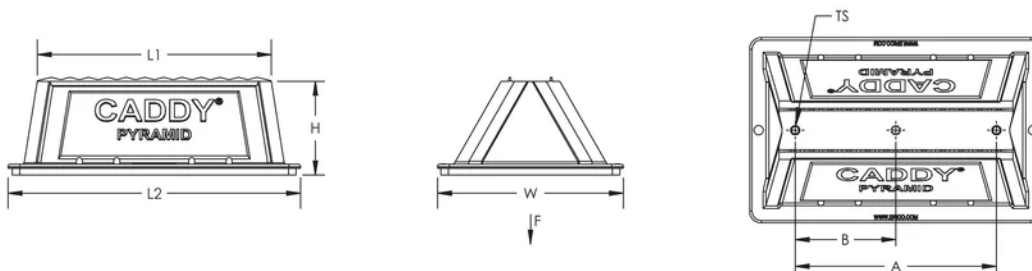

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência
técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

