

nVent CADDY Rod Lock Metal Decking Preset Anchor



CERTIFICATIONS



CARACTERÍSTICAS

Set in place through a drilled hole in the metal decking before the concrete is poured

Eliminate overhead drilling into building structure - nVent CADDY Rod Lock Preset Anchors are cast in place

Easy "push-to-install" design allows installers to simply push the threaded rod through the mounting hole, instantly holding it in position

Can be used in lower and upper flute installations

Works with slightly damaged threads and minor burrs on the threaded rod

Prefabricated assemblies easily lift and lock into place, helping to save time and money

Plastic flange acts as insert locator when the forms are removed

Rated for cracked concrete per ICC-ES AC446 according to ICC-ES ESR-3864 evaluation report

Suitable for seismic bracing according to ICC-ES ESR-3864 evaluation report

Plenum-rated for use in air-handling spaces based on testing according to ANSI/UL 2043

ESPECIFICAÇÕES

Acabamento: Electrogalvanized

Material: Aço



Table 1/2

Número de catálogo	Tamanho da haste (RS)	Diâmetro 1 (Ø1)	Diâmetro 2 (Ø2)	Altura (H)	Length (L)	Largura (W)
CRLM37EG	0.375	42 mm	17.8 mm	142.2 mm	71.1mm	38.1 mm
CRLM50EG	0.5	49.5 mm	20.3 mm	144.8 mm	71.1mm	38.1 mm

Table 2/2

Número de catálogo	A	Diâmetro da broca	Static Load
CRLM37EG	58.42 mm	19mm	3700N
CRLM50EG	60.96 mm	22mm	3700N

DIAGRAMAS

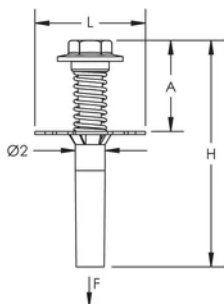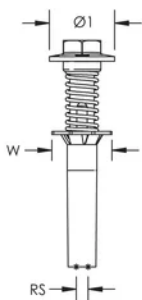

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência
técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

