

nVent CADDY Superfix 454 Standard Duty



CARACTERÍSTICAS

Recommended for the suspension of stationary non-insulated pipe lines

Easy-to-close clamp for steel pipe and copper tube

Unique hinged design eliminates the need to disassemble the clamp prior to installation

Clamp can be closed with one hand, without ever turning a screw

All-steel design of the closing mechanism retains strength even when exposed to heat

Comes with a welded 3/8" cap nut, allowing easy attachment to threaded rod

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

ESPECIFICAÇÕES

Acabamento: Electrogalvanized

Temperatura: -50 to 110 °C

Table 1/1


Número de catálogo	Material	Diâmetro externo (OD)	Copper Tube Size	B	Static Load
454001	Aço, EPDM-SBR Rubber	12.7 mm	3/8"	23.02 mm	800N

Número de catálogo	Material	Diâmetro externo (OD)	Copper Tube Size	B	Static Load
454002	Aço, EPDM-SBR Rubber	15.9 - 17.1 mm	1/2"	23.02 mm	800N
454003	Aço, EPDM-SBR Rubber	19.1 mm	5/8"	23.02 mm	800N
454004	Aço, EPDM-SBR Rubber	21.3 - 22.2 mm	3/4"	23.02 mm	800N
454005	Aço, EPDM-SBR Rubber	26.7 - 28.6 mm	1"	23.02 mm	800N
454006	Aço, EPDM-SBR Rubber	33.4 - 34.9 mm	1 1/4"	23.02 mm	800N
454007	Aço, EPDM-SBR Rubber	42.2 mm Min	1 1/2"	23.02 mm	800N
454008	Aço, EPDM-SBR Rubber	48.0 - 48.3 mm		23.02 mm	800N
454009	Aço, EPDM-SBR Rubber	54 mm	2"	23.81 mm	800N
454010	Aço, EPDM-SBR Rubber	57.0 - 60.3 mm		23.02 mm	800N
454011	Aço, EPDM-SBR Rubber	63.0 - 66.7 mm	2 1/2"	23.02 mm	1330N
454012	Aço, EPDM-SBR Rubber	69.7 - 73 mm		23.81 mm	1330N
454013	Aço, EPDM-SBR Rubber	73.8 - 79.4 mm	3"	23.81 mm	1330N
454014	Aço, EPDM-SBR Rubber	83.0 - 88.9 mm		23.81 mm	1330N
454015	Aço, EPDM-SBR Rubber	92.1 mm	3 1/2"	23.02 mm	1330N
454016	Aço, EPDM-SBR Rubber	101.6 - 104.8 mm	4"	28.57 mm	1330N
454017	Aço, EPDM-SBR Rubber	108.0 - 114.3 mm		28.57 mm	1330N

DETALHES ADICIONAIS DO PRODUTO

Lining is EPDM rubber.

DIAGRAMAS

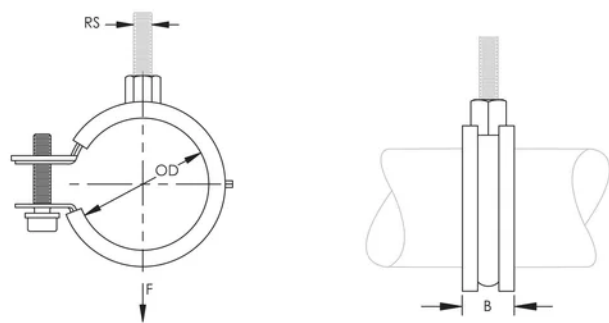

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência
técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

