


Grid Straps for ProLine Frames 3-Row, 1200mm, Galvanized, Mild Steel

Data Solutions

NÚMERO DE CATÁLOGO

PGH3S12

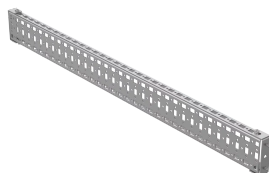

The Grid Straps are provided with specially designed rectangular holes to allow the use of cage nuts or front-loading cage nuts. Mounting holes are provided on 25-mm centers. Grid Straps are available with either 1 row or 3 rows of holes and are furnished in pairs. Mounting hardware to attach Grid Straps to the frame or to other Grid Straps is included.

CARACTERÍSTICAS

Can be mounted vertically between horizontally mounted Grid Straps

Can be mounted left-to-right horizontally between front-to-back pairs or from the sides of the ProLine frame

Can be mounted front-to-back horizontally across the bottom or sides of the ProLine frame

When mounting width-wise from vertical to vertical, the grid strap chosen must be 100mm greater than the nominal size (i.e. 800mm wide enclosure would take a 900mm grid strap in this orientation)

Furnished in pairs, and constructed from 14 gauge (1.75mm) conductive steel

CARATERÍSTICAS DO PRODUTO

Número do artigo: 16028

Material: Aço Macio

Fits Frame Depth: 1200mm

Padrão do orifício: Three Rows

Acabamento: Galvanizado

Espessura: 1.9mm

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE