


nVent CADDY Cat 425 Adjustable Cable Support with BC Beam Clamp

Data Solutions

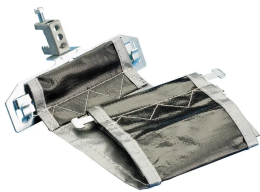

CERTIFICATIONS



CARACTERÍSTICAS

Easy installation to beam flanges

Rotates 360 degrees to support various directional runs of cable

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Simple unlocking and locking of bar allows for additional cables to be added easily after installation

Adjustable strap allows for multiple support sizes to reduce inventory

Cost effective alternative to expensive cable tray

cULus® Listed and complies with NEC® and TIA requirements for structured cabling systems

Suitable for air handling spaces (plenum)

ESPECIFICAÇÕES


Table 1/2

Número de catálogo	Material	Acabamento	Diâmetro (Ø)	Area	Cable Capacity, Cat 5e	Cable Capacity, Cat 6
CAT425BC	Aço, Polietileno	nVent CADDY Armour, Electro galvanizado	100mm, 150mm	518mm ²	425	325

Table 2/2

Número de catálogo	Cable Capacity, Cat 6A	Espessura do flange (FT)	Static Load
CAT425BC	210	3.2 – 12.7mm	450N

DIAGRAMAS

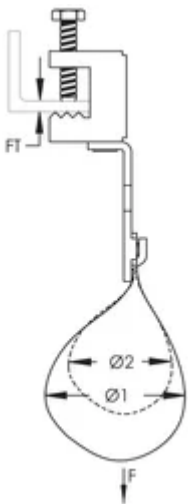

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE