

nVent CADDY Cat HP J-Hook Clip to BC Beam Clamp, Swivel

Data Solutions



CERTIFICATIONS



CARACTERÍSTICAS

Easy installation to beam flanges

Rotates 360 degrees to support various directional runs of cable

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook


ESPECIFICAÇÕES

Table 1/1

Número de catálogo	Número do artigo	Material	Acabamento	Espessura do flange (FT)	Static Load
--------------------	------------------	----------	------------	--------------------------	-------------

CATHPBCB	181073	Aço, Spring Aço	Electrogalvanized, nVent CADDY Armour	3.2 – 16mm	267N
----------	--------	-----------------	---	------------	------

DIAGRAMAS

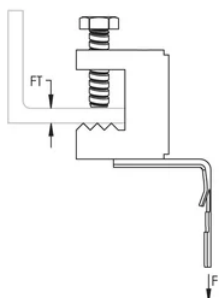

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE