

Flat Terminal Connection



CERTIFICATIONS



CARACTERISTICAS

Connects nVent ERIFLEX Flexibar or IBSB/IBSBR Power Braid to UD-250A/400A Single Pole Distribution Block

Provides direct link between blocks and switch or circuit breakers


Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

ESPECIFICAÇÕES

Table 1/1

Número de catálogo	Número do artigo	Tamanho do orifício (HS)	A	B	Peso unitário
FLG250	569160	10.8 mm	25 mm	35 mm	0.05 kg
FLG400	569170	10.8 mm	30 mm	40 mm	0.1 kg

DIAGRAMAS

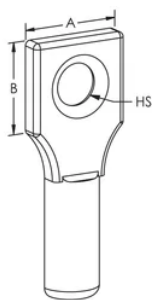

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência

técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE