

SBTT-350 Tunnel-to-Tunnel Power Terminal



CERTIFICATIONS



CARACTERÍSTICAS

Tinned copper block allows for copper or aluminum conductor connections

Accessible tunnels allow for easy connection of wire

Design allows for visual inspection of conductor and confirmation of connection

Adjustable transparent cover

Modular snap-together blocks for building multi-pole power blocks

Easily clips onto DIN rail or mounts to panel with screws

SBLEC Power Terminals Fixing Accessory required for direct panel mount

RoHS compliant

Halogen free

ESPECIFICAÇÕES


Número de catálogo	SBTT-350
Número do artigo	561143
Material	Copper Termoplástico

Número de catálogo	SBTT-350
Acabamento	Tinned
Max Current Rating, IEC	500A
Max Current Rating, UL/CSA	310A
Short Term Withstand Current (I _{cw}) 1s	22.2kA
Peak Short Circuit Current (I _{pk})	43kA
Classificação de corrente de curto-circuito (SCCR)	100kA
Max Working Voltage, IEC (U _i)	1000 1500
Max Working Voltage, UL (V _{in})	1000
Number of Tunnel Connections	2
Tunnel Connection Compact Stranded Wire Size	(2) 35 – 185 mm ²
Tunnel Connection Wire Size - Ferrule	(2) 35 – 150 mm ²
Tunnel Connection Wire Size	(2) #2 – 350 kcmil
Profundidade (D)	66mm
Altura (H)	205.7 mm
Largura (W)	52.3 mm
A	108 mm
Peso unitário	0.33 kg
Certification Details	UL® 1059
Flammability Rating	UL® 94V-1
Em conformidade com	IEC® 60947-7-1

DETALHES ADICIONAIS DO PRODUTO

Power terminal connections are interchangeable and can be used as line side or load side connections.

DIAGRAMAS

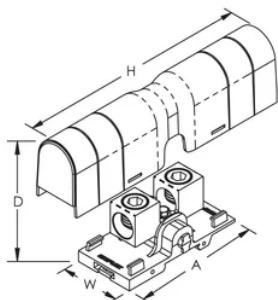

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência
técnica

Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE