

TDL Compact Four Pole Distribution Block, 400 A



CERTIFICATIONS



CARACTERISTICAS

Connect nVent ERIFLEX Flexibar, insulated braided conductor or cable with lug on line side

Tinned copper bars allows for copper or aluminum cable

Transparent protection covers

Easy and safe connections

Easily clips onto DIN rail or mounts to panel with screws

Solid bars provide reliability

Input separated from outputs

Supports wiring from both sides

Design allows for visual inspection of conductor and confirmation of connection

Large end terminals

High percentage of fill ratio

Wiring with or without terminal

RoHS compliant

Conforms to EN 45545 obtaining an HL3 classification for chapter R23 and HL2 classification for chapter R22

Halogen free


ESPECIFICAÇÕES

Número de catálogo	TDL-400A
Número do artigo	563995
Material	Copper Termoplástico
Acabamento	Tinned
Max Current Rating, IEC	400A
Max Current Rating, UL/CSA	400A
Short Term Withstand Current (Icw) 1s	23kA
Peak Short Circuit Current (Ipk)	51kA
Max Working Voltage, IEC (Ui)	1000 1500
Max Working Voltage, UL (Vin)	600
Line Side Number of Connections	1
Line Side Compact Stranded Wire Size	35 - 120 mm ²
Line Side Conductor Width	20 - 24 mm
Line Side Stranded Wire Size - Ferrule	35 - 120 mm ²
Line Side Wire Size	1 - 250
Load Side Number of Connections	14
Load Side Compact Stranded Wire Size	(1) 10 - 50 mm ² (2) 10 - 35 mm ² (4) 6 - 25 mm ² (7) 2,5 - 16 mm ²
Load Side Stranded Wire Size - Ferrule	(1) 10 - 35 mm ² (2) 10 - 25 mm ² (4) 6 - 16 mm ² (7) 2,5 - 10 mm ²
Load Side Wire Size	(1) #6 - 1/0 (2) #8 - #1 (4) #10 - #3 (7) #10 - #5
Profundidade (D)	121mm
Altura (H)	156 mm
Largura (W)	224 mm
Peso unitário	1.69 kg
Classificação do gabinete	IP 10
Flammability Rating	UL® 94V-0
Em conformidade com	IEC® 60947-7-1

DETALHES ADICIONAIS DO PRODUTO

Line side and load side number of connections are per pole.

DIAGRAMAS

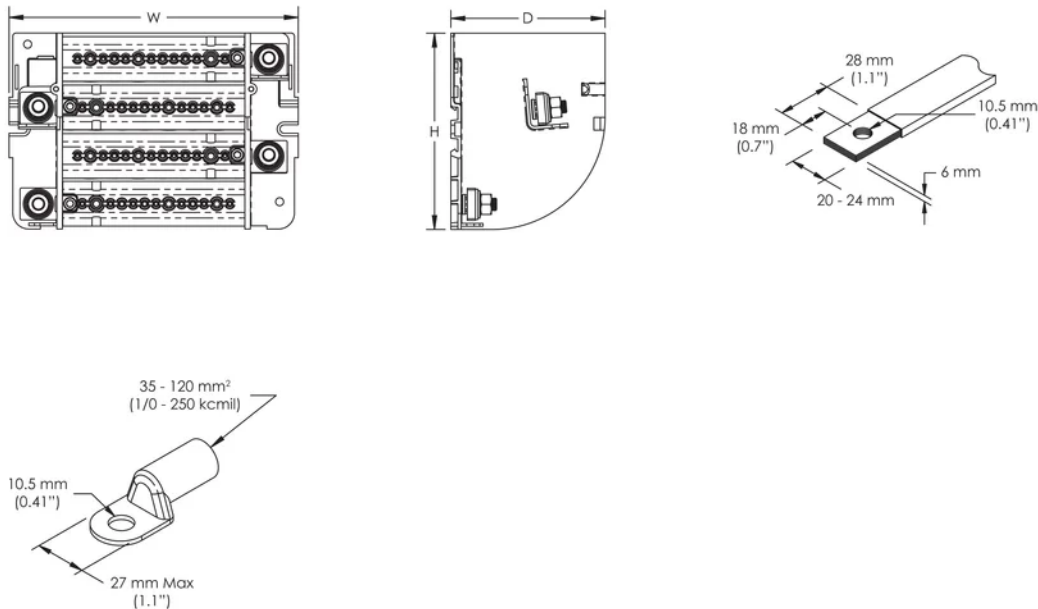

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE