

Vertical Pouring Basin, Extended



Extended vertical pouring basins are used when interferences of the structure are directly next to the tap hole in the sleeve.

CARACTERÍSTICAS

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series vertical sleeves

ESPECIFICAÇÕES

Material: Graphite

Table 1/1

Número de catálogo	Diâmetro (Ø)	Comprimento 1 (L1)	Comprimento 2 (L2)	Largura (W)	Altura 1 (H1)	Altura 2 (H2)
RBVB11065X	38 mm	279 mm	38 mm	76 mm	165mm	76mm
RBVA7570J	76 mm	191 mm	38 mm	76 mm	178mm	76mm
RBVA9060F	64 mm	229 mm	38 mm	76 mm	152mm	76mm
RBVA9095F	64 mm	229 mm	38 mm	76 mm	241mm	76mm
RBVA9095M	95 mm	229 mm	38 mm	76 mm	241mm	76mm
RBVB12060E	57 mm	305 mm	38 mm	76 mm	152mm	76mm

Número de catálogo	Diâmetro (Ø)	Comprimento 1 (L1)	Comprimento 2 (L2)	Largura (W)	Altura 1 (H1)	Altura 2 (H2)
RBVB12065F	64 mm	305 mm	38 mm	76 mm	165mm	76mm
RBVB12070M	95 mm	305 mm	38 mm	76 mm	178mm	76mm
RBVB14065F	64 mm	356 mm	38 mm	76 mm	165mm	76mm
RBVB14075M	95 mm	356 mm	38 mm	76 mm	191mm	76mm
RBVB14080J	64 mm	356 mm	38 mm	76 mm	203mm	76mm
RBVB16575E	95 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB16575J	76 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB16575M	95 mm	419 mm	38 mm	76 mm	191mm	76mm
RBVB17075D	76 mm	432 mm	38 mm	76 mm	191mm	76mm
RBVB17710F	64 mm	451 mm	38 mm	76 mm	254mm	76mm
RBVB17710M	95 mm	451 mm	38 mm	76 mm	254mm	76mm


DETALHES ADICIONAIS DO PRODUTO

RBVA pouring basins require one RBM2660DC pouring basin frame and one RBS5000 bolt retainer. RBVB pouring basins require one RBM2660TC pouring basin frame and one RBS5000 bolt retainer (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMAS

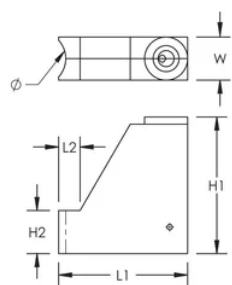

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

América do Norte

+1 800 753 9221
Opção 1 – Apoio ao cliente
Opção 2 – Assistência
técnica

Europa

Países Baixos:
+31 800-0200135
França:
+33 800 901 793

Europa

Alemanha:
800 1890272
Outros países:
+31 13 5835404

APAC

Xangai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



O nosso forte portefólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE