


U-profile Front Panel, Shieldable, D-Sub Cutouts, 3 U, 4 HP, 1 x 9 Pin

Power Utilities

NÚMERO DE CATÁLOGO

30849-749

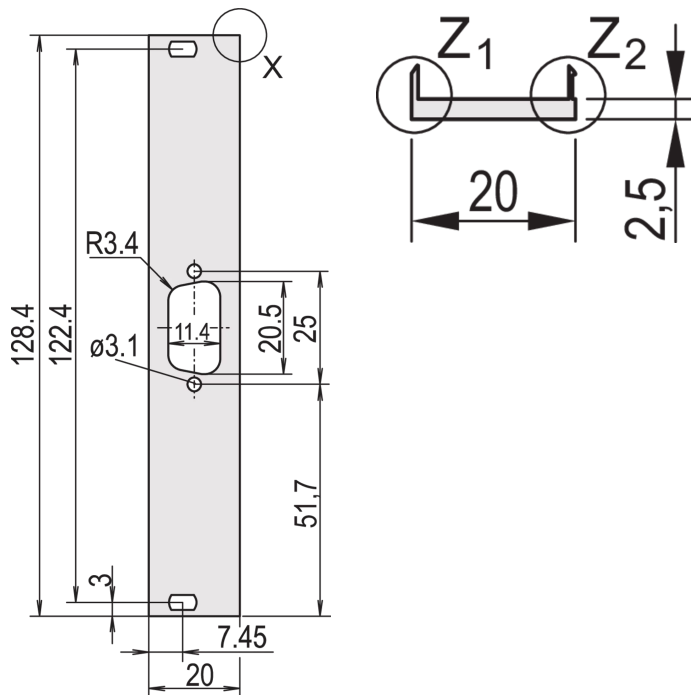

U-profile front panel with cutout for D-Sub connectors. Shieldable for textile EMC gasket.

CERTIFICATIONS



CARACTERÍSTICAS

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

CARACTERÍSTICAS DO PRODUTO

Product Type: Front Panel

Tipo: Front Panel without Handle

Instalação: Screw-on Front

EMC Shielding: No (Retrofittable)

Gasket Type: Textile

Material: Alumínio

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Não

Rack Height: 3 U

Altura: 128.4 mm

Rack Width: 4 HP

Largura: 20 mm

Em conformidade com: IEC 60297-3-101; IEEE 1101.1/10

Quantidade por embalagem: 5

DETALHES ADICIONAIS DO PRODUTO

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE