


# EuropacPRO Cover Plate for Bolting to Side Panel

## Power Utilities

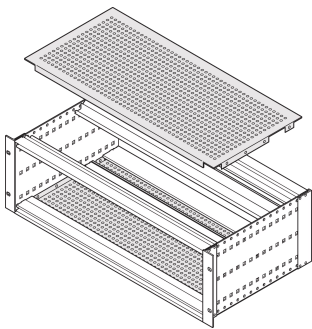

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

### CERTIFICATIONS



### CARACTERÍSTICAS

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

### ESPECIFICAÇÕES

Table 1/2

| Número de catálogo | Rack Width | Profundidade | Quantidade por embalagem | Família de produtos | Product Type | Tipo       |
|--------------------|------------|--------------|--------------------------|---------------------|--------------|------------|
| 24560-064          | 42 HP      | 175 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-065          | 42 HP      | 235 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |

| Número de catálogo | Rack Width | Profundidade | Quantidade por embalagem | Família de produtos | Product Type | Tipo       |
|--------------------|------------|--------------|--------------------------|---------------------|--------------|------------|
| 24560-066          | 42 HP      | 295 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-071          | 63 HP      | 175 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-072          | 63 HP      | 235 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-073          | 63 HP      | 295 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-078          | 84 HP      | 175 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-079          | 84 HP      | 235 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-080          | 84 HP      | 295 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-081          | 84 HP      | 355 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-082          | 84 HP      | 415 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-083          | 84 HP      | 475 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-061          | 42 HP      | 275 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-062          | 63 HP      | 275 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24560-063          | 84 HP      | 275 mm       | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24579-090          | 42 HP      | 277.75 mm    | 1                        | EuropacPRO          | Cover Plate  | Perforated |
| 24579-092          | 84 HP      | 277.75 mm    | 1                        | EuropacPRO          | Cover Plate  | Perforated |

Table 2/2

| Número de catálogo | Works With | Unidade de embalagem | Torque  |
|--------------------|------------|----------------------|---------|
| 24560-064          | Subracks   | Pair                 | 2.1 N·m |
| 24560-065          | Subracks   | Pair                 | 2.1 N·m |

| Número de catálogo | Works With | Unidade de embalagem | Torque  |
|--------------------|------------|----------------------|---------|
| 24560-066          | Subracks   | Pair                 | 2.1 N·m |
| 24560-071          | Subracks   | Pair                 | 2.1 N·m |
| 24560-072          | Subracks   | Pair                 | 2.1 N·m |
| 24560-073          | Subracks   | Pair                 | 2.1 N·m |
| 24560-078          | Subracks   | Pair                 | 2.1 N·m |
| 24560-079          | Subracks   | Pair                 | 2.1 N·m |
| 24560-080          | Subracks   | Pair                 | 2.1 N·m |
| 24560-081          | Subracks   | Pair                 | 2.1 N·m |
| 24560-082          | Subracks   | Pair                 | 2.1 N·m |
| 24560-083          | Subracks   | Pair                 | 2.1 N·m |
| 24560-061          | Subracks   | Pair                 |         |
| 24560-062          | Subracks   | Pair                 |         |
| 24560-063          | Subracks   | Pair                 |         |
| 24579-090          | Subracks   | Pair                 | 2.1 N·m |
| 24579-092          | Subracks   | Pair                 | 2.1 N·m |

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**