


Novastar 19" Panel/Slide Mount

Concessionárias de energia

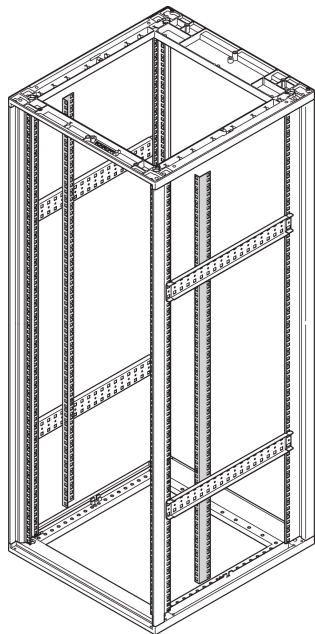

Novastar 19" Panel/Slide Mount Kit with load capacity of 400 kg, ensures easy fitting of 19" components to depth members.

CERTIFICAÇÕES



RECURSOS

For recessed installation of 19" components

For fitting to depth members (25 mm grid)

Load carrying capacity 400 kg

ESPECIFICAÇÕES

Table 1/2

Número do catálogo	Rack Height	Package Quantity	Cor	Color Code	Altura	Product Type
--------------------	-------------	------------------	-----	------------	--------	--------------

27230-179	38 U	1	Black Grey	RAL 7021	1689.5 mm	Slide Mount
27230-176	20 U	1	Black Grey	RAL 7021	889.4 mm	Slide Mount
27230-174	12 U	1	Black Grey	RAL 7021	533.8 mm	Slide Mount
27230-180	43 U	1	Black Grey	RAL 7021	1911.75 mm	Slide Mount
27230-175	16 U	1	Black Grey	RAL 7021	711.6 mm	Slide Mount
27230-173	9 U	1	Black Grey	RAL 7021	400.45 mm	Slide Mount
27230-177	25 U	1	Black Grey	RAL 7021	1111.65 mm	Slide Mount
27230-178	34 U	1	Black Grey	RAL 7021	1511.7 mm	Slide Mount
27230-172	6 U	1	Black Grey	RAL 7021	267.1 mm	Slide Mount
27230-181	47 U	1	Black Grey	RAL 7021	2089.55 mm	Slide Mount

Table 2/2

Número do catálogo	Package Unit
27230-179	Pair
27230-176	Pair
27230-174	Pair
27230-180	Pair
27230-175	Pair
27230-173	Pair
27230-177	Pair
27230-178	Pair

Número do catálogo	Package Unit
27230-172	Pair
27230-181	Pair

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE