


Novastar Base/Plinth

Concessionárias de energia

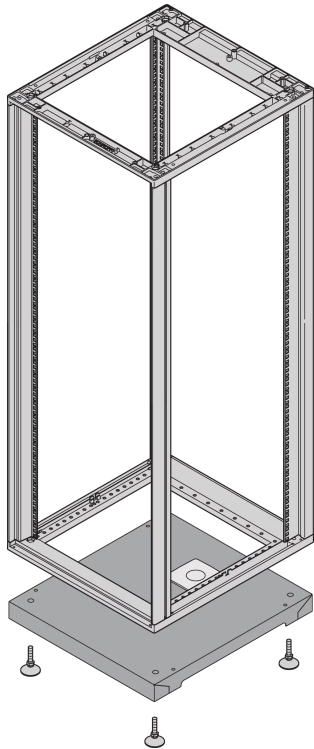

Base Plate for Rear Cable Ducting which cut out for cable management. Opening is covered with plastic. Accessory brush strip can build in.

CERTIFICAÇÕES



RECURSOS

Static load-carrying capacity 400 kg

Adjustable feet, height 57 mm ... 67 mm

St, 1.5 mm, RAL 7021

Cable ducting 110 x 76 mm

Incl. GND/earthing

ESPECIFICAÇÕES

Table 1/2

Número do catálogo	Largura	Profundidade	Cor	Color Code	Altura	Product Type
27230-070	553 mm	500 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-071	553 mm	600 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-072	553 mm	800 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-076	900 mm	900 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base
27230-080	1000 mm	1000 mm	Black Grey	RAL 7021	45 mm	Cabinet/Rack Base

Table 2/2

Número do catálogo	Tipo
27230-070	Base Plinth
27230-071	Base Plinth
27230-072	Base Plinth
27230-076	Base Plinth
27230-080	Base Plinth

ADDITIONAL PRODUCT DETAILS

Please order brush strip separately.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE